



ALPHA 630, Floor-mounted cabinet, IP44, Protection class 1, H: 1950 mm, W: 1300 mm, T: 210 mm, RAL 7035, incl. flange in roof

Model			
product brand name		ALPHA	
product designation		Free-standing cabinet	
surface processing		powder-coated	
Protection class			
protection class IP		IP44	
operating resource protection class		Safety class 1	
IK protection class		IK09	
suitability for interaction lightning protection		Yes	
suitability for use for outside use		No	
Appearance			
RAL color number		7035	
product component			
• cable entry	Yes		
• mounting plate	No		
special product feature		incl. flange in the roof	
product extension optional side-by-side mounting		Yes	
number of rows		60	
Mechanical Design			
height		1 950 mm	
width		1 300 mm	
depth		210 mm	
installation depth		210 mm	
number of modular width units		720	
number of modular width units per DIN mounting bar		12	
fastening method		floor mounting	
net weight		71 kg	
material of the enclosure		Steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



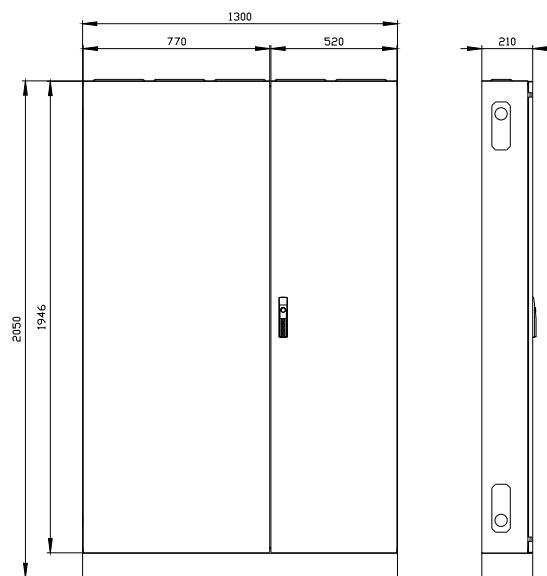
[Special Test Certificate](#)

[Miscellaneous](#)

[Confirmation](#)

Environment

[Environmental Con-](#) [Environmental Con-](#)

Further information**Information on the packaging**<https://support.industry.siemens.com/cs/ww/en/view/109813875>**Information- and Downloadcenter (Catalogs, Brochures,...)**<http://www.siemens.com/lowvoltage/catalogs>**Industry Mall (Online ordering system)**<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8GK1322-8KA52>**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**<https://support.industry.siemens.com/cs/ww/en/ps/8GK1322-8KA52>**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8GK1322-8KA52**CAX-Online-Generator**<http://www.siemens.com/cax>**Tender specifications**<http://www.siemens.com/specifications>

last modified:

5/26/2025

