

1-1437361-8 ✓ ACTIVE

MADISON CABLE


TE Internal #: 1-1437361-8

Ribbon & Flat Cable, 20 Conductors, PVC, Operating Temperature Range -20 – 105 °C, Length 100 ft [30.5 m], Gray, Tinned Copper, 46 pF/ft, 100 Ω

[View on TE.com >](#)



Wire & Cable > Ribbon & Flat Cable

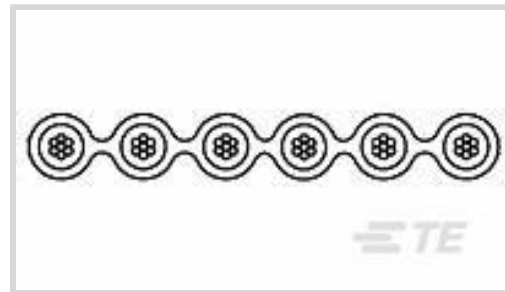

Number of Conductors: 20

Shielded: No

Insulation Material: PVC

Operating Temperature Range: -20 – 105 °C

Length: 30.5 m [100 ft]

Features

Product Type Features

Product Category	Ribbon Cable
Product Type	Cable
Wire/Cable Type	Ribbon Cable
Product Classification	Cable - Flat Ribbon
Shielded	No

Configuration Features

Number of Conductors	20
Number of Strands	19

Electrical Characteristics

Propagation Delay	4.53 ns/m
Current Rating	2 A
	46 pF/ft
Impedance	100 Ω
Voltage Rating	300 V

Body Features

Jacket Color	Gray
Jacket Material	PVC
Insulation Material	PVC

Conductor Insulation Color	Gray
----------------------------	------

Conductor Material	Tinned Copper
--------------------	---------------

Housing Features

Centerline	1.27 mm[.05 in]
------------	-----------------

Dimensions

Cable Insulation Height	.89 mm[.035 in]
-------------------------	-----------------

Cable Insulation Width	25.4 mm[1 in]
------------------------	---------------

Length	30.5 m[100 ft]
--------	----------------

Wire Size	.08 mm ²
-----------	---------------------

Strand Size	40 AWG
-------------	--------

Usage Conditions

Operating Temperature Range	-20 – 105 °C
-----------------------------	--------------

Packaging Features

Packaging Method	Reel
------------------	------


Packaging Quantity	30 m[98.43 ft]
--------------------	----------------

Compatible Parts



Customers Also Bought





TE Model / Part #1437361-8
185-14=14P 28AWG STRAND PVC HF




TE Model / Part #1437361-3
185-10=10P 28AWG ST



TE Model / Part #1-1437361-5
185-16=16P 28AWG ST



TE Model / Part #641201-5
05P MTA100 CONN ASSY GRN 28AWG

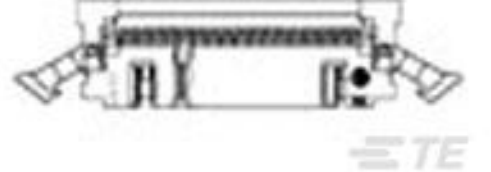

TE Model / Part #1-111504-6
016 UNIV I/O 30DP NO EARS LTCH

Documents

Product Drawings

185-20=20P 28AWG STRAND PVC HF

English

185-20=20P 28AWG STRAND PVC HF

English

Product Environmental Compliance

Product Compliance

English

Product Compliance

English