







ENCLOSURE FOR COMMAND DEVICES, 22MM, ROUND,
ENCLOSURE MATERIAL PLASTIC, ENCLOSURE TOP PART
YELLOW, 1 COMMAND POINT, UNEQUIPPED, FLOOR
MOUNTING, 1 X M20 EACH AT TOP AND BOTTOM



Enclosure:	
Design of the housing	Empty enclosure for command and signaling devices
Shape of the enclosure front	Square
Material of the enclosure	plastic
Number of command points	1
Product component	
• protective collar	No
Color	
• of top part of the enclosure	yellow
Delivery state	
• as a kit	No
• pre-wired on strip terminal	No
Mounting type of the enclosure	Vertical / horizontal
Actuator:	
Product feature	
• lockout	No
Product expansion optional Light source	Yes
Front ring:	

Product component front ring	No
General technical data:	
Product function	
• positive opening	No
• EMERGENCY STOP function	No
Product component	
• Light source	No
• Stand/pedestal	No
Protection class IP	IP65
Vibration resistance	
• acc. to IEC 60068-2-6	20 ... 200 Hz: 5g
Equipment marking	
• acc. to DIN 40719 extended according to IEC 204-2 acc. to IEC 750	S
• acc. to DIN EN 61346-2	U
• acc. to DIN EN 81346-2	U
Connections/ Terminals:	
Type of electrical connection on enclosure	Cable routing above, below / left, right, each 1 x M20
Ambient conditions:	
Ambient temperature	
• during operation	-25 ... +70 °C
• during storage	-40 ... +80 °C
Environmental category during operation acc. to IEC 60721	3K6
Installation/ mounting/ dimensions:	
Mounting type	
• of contact blocks, socket, and accessories	Floor mounting / front mounting (1-pole)
Height	85 mm
Width	85 mm
Depth	64 mm
Shape of the installation opening	round
Mounting diameter	22 mm
Accessories:	
Number of labels	1
Product component holder for 3 switching elements	No
Certificates/approvals	

General Product Approval		Declaration of Conformity	Test Certificates	Shipping Approval
 CSA	 UL		 EG-Konf.	spezielle Prüfbescheinigung <u>n</u>  ABS

Shipping Approval	other
 DNV	 LRS
 PRS	Umweltbestätigung Bestätigungen

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SB38010AB3>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SB38010AB3>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3SB38010AB3>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SB38010AB3&lang=en

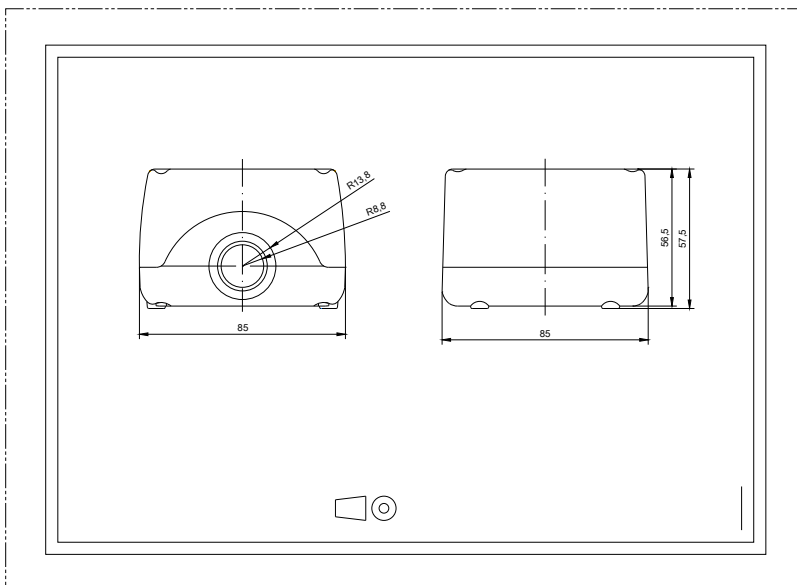

last modified:

13.02.2016