


76.SLS - FORGED METRIC-SIZE AND INCH-SIZE 12 X 6 POINT ANGLED OPEN-SOCKET WRENCHES - SLS | 76.14SLS

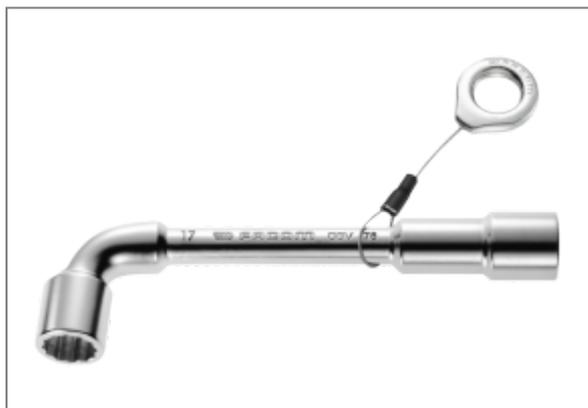

Description

- Tool fitted with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The « turning » crimped cable solution, chosen and tested by FACOM, preserves the ergonomics of use of the tool.
- Open-socket wrenches for powerful (un)tightening.
- 12-point short head for 30° increment and 6-point long-reach head.
- Short head open socket for passing threaded rods.
- Metric dimensions: 8 to 32 mm.
- Satin chrome finish.

Information

A [mm]	14
B [mm]	21,0
d [mm]	10,5
d1 [mm]	9
H [mm]	32
L [mm]	160
L1 [mm]	40
[g]	215