




CM-TD RX7s 70W 830 WDL

Article number: 146466

BAI CM-TD RX7s 85V 70W 3000K 6400lm 20x119mm V±45° CRI80-90 10.000u Ceramic Metal Halide CMH-TD CDM-TD HQI-TS CMI-TD HRI-TS RCC-TS Compact halogen metal halide lamp

The Ceramic Metal Halide (CMH/CDM) lamps from Bailey Lights continue to offer possibilities for lighting design where a LED can't be used yet. These lamps provide excellent overall light quality, excellent lumen maintenance, efficiency while maintaining long life and reliability. The lamp base is ceramic. These lamps are often used in shops, shop windows and museums.

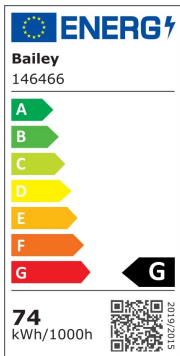

General ETIM properties

ETIM group	Lamps
ETIM class	Halogen metal halide lamp without reflector
Name	CM-TD RX7s 70W 830 WDL
Brand	Bailey
Productseries	HID
Producttype	CM-TD RX7s

ETIM specifications

Socket	RX7s
Lamp power [W]	70
Colour temperature [K]	3000
Luminous flux [lm]	6400
Lamp voltage [V]	85 - 85
UV protection	Yes
Colour rendering index CRI	80-89
Colour of light according to EN 12464-1	Warm white < 3300 K
Lamp efficacy [lm/W]	92
Lamp shape	Tube, double-ended
Material discharge tube	Ceramics
Burning position	h45
Diameter [mm]	20
Total length [mm]	119
External ignitor required	Yes
External ballast required	Yes
Closed luminaire required	Yes
Sun tanning lamp	No
Colour	Colourless
Colour of light	830
Model	Clear
Lamp designation	TD
Weighted energy consumption in 1000 hours [kWh]	74
Average nominal lifetime [h]	10000
Energy efficiency class according to EU regulation 2019/2015	G

Alternative articles



VEN00370
CM-Plus TD
70W/U/UVS/RX7s/830



HMC070830TD/01
MASTERC CDM-TD 70W/830
RX7s

Complementary articles



92200219199

POWERTRONIC INTELLIGENT
PTi | 70/220...240 |