


## ST25 250W SOLDERING IRON

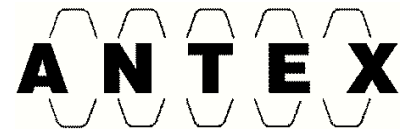

### DATA SHEET


**769-3078**



Iron featured excluding bit

#### **SPECIFICATIONS ST25 (STRAIGHT) 250WATT SOLDERING IRON**

NOMINAL POWER (W)	250
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	460
FITTED BIT (D.F.)	¾" (19mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with British plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	850
DIMENSIONS (approx)	A: (bit) 50mm. B: (handle & element) 250mm.

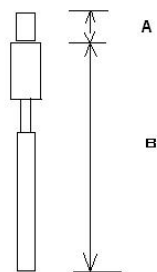

#### **TYPICAL APPLICATIONS:**

Used particularly with higher temperature alloys on commutators.