




Product information

Name: Speedi-Roll

Designation: LLEHS 15 Speedi-Roll

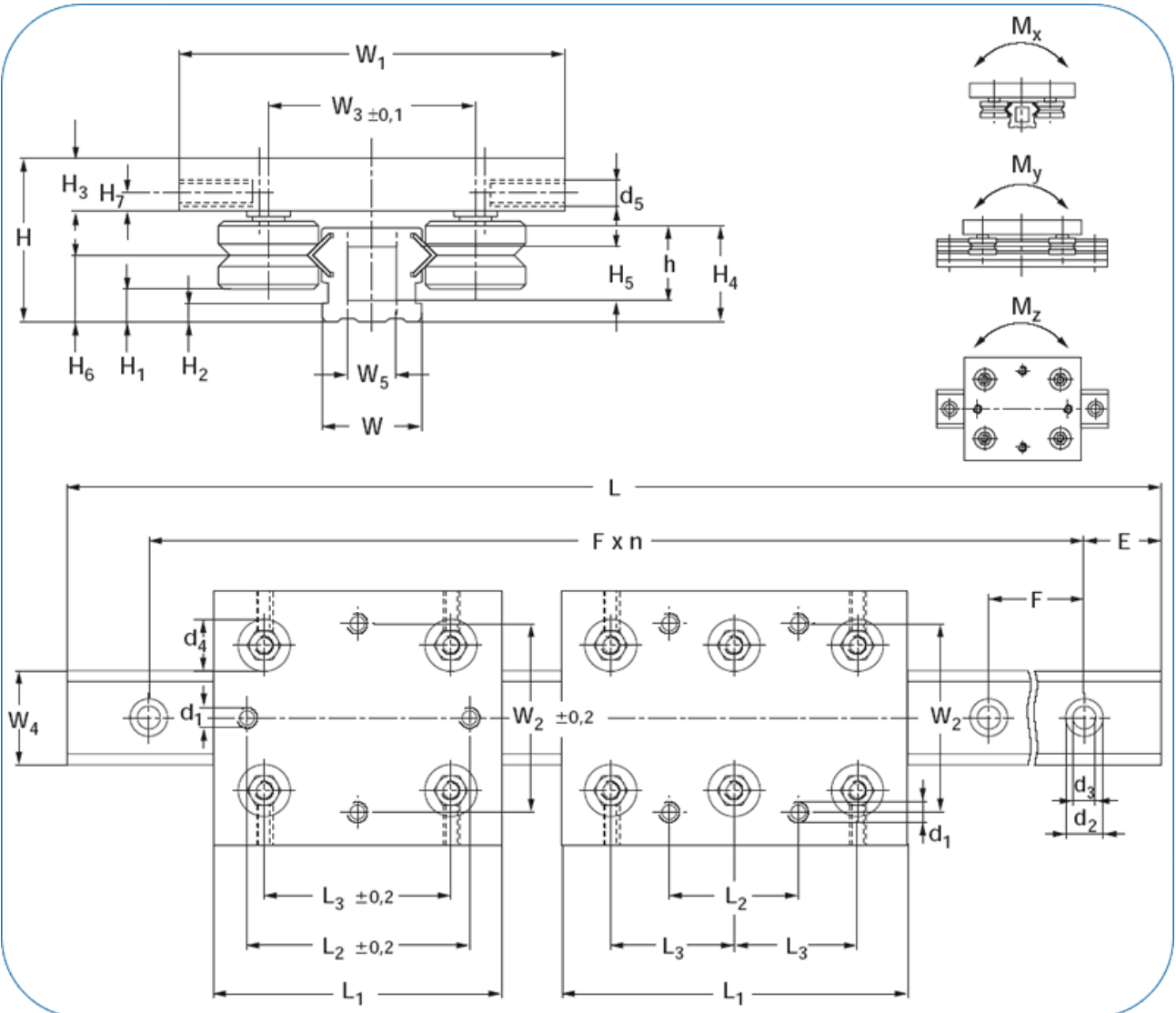

Product specifications

Range		Guiding system
H	[mm]	25
H1	[mm]	3,75
W1	[mm]	65
Carriage type		Standard

Please choose your country with the top menu

Product specifications (Next page)

L1	[mm]	70
W2	[mm]	50
L2	[mm]	60
W3	[mm]	40,2
L3	[mm]	45
H3	[mm]	6,05
d1		M 5
d4	[mm]	14
rail width	W [mm]	18
W4	[mm]	24,9
H2	[mm]	2
H4	[mm]	17
H6	[mm]	10,75
d2	[mm]	9,5
d3	[mm]	5,5
h	[mm]	8,5
F	[mm]	62,5
E	[mm]	31,25
L	[mm]	4 000
Foy	[N]	700
Foz	[N]	660
Mox	[Nm]	10
Moy	[Nm]	12
Moz	[Nm]	6
weight of rail	[kg]	0,9
weight of carriage	[kg]	0,2