
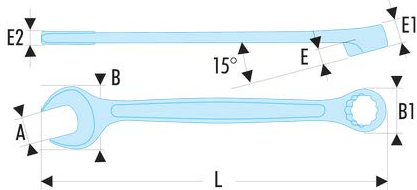


440.9/16SLS 440.SLS - Inch combination wrenches

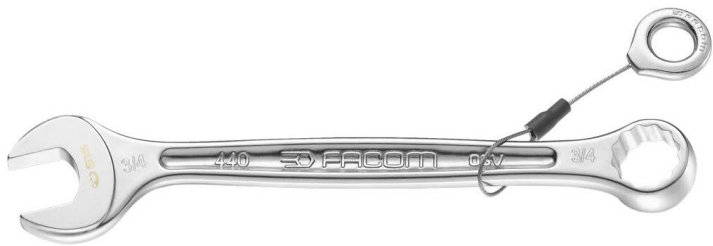

Description :

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "sliding" cable solution, selected and tested by FACOM, maintains user ergonomics (8 - 30 mm wrenches).
- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
  - Ring open end (size E) designed for better access to series or embedded screws.
  - OGV® profile with 12-point ring for powerful tightening while protecting the nut.
  - Ring head angled at 15°.
- Open end head:
  - Open end angled at 15°.
  - Open end head-handle geometry optimised for increased access.
- Dimensions in inches: from 1/4" to 1"5/16.
- Presentation: satin chrome finish.

A ["]:	9/16
B [mm]:	31,0
B1 [mm]:	21,1
C1 [mm]:	9,5
E [mm]:	5,7
E1 [mm]:	9,5
E2 [mm]:	6,4
L [mm]:	180
[g]:	100