

Data sheet article 85V410


Stainless steel tubular cable lug

heat resistant up to 400° C
for aggressive environmental factors
ring type

cross section 35mm², Bolt size M10



A:	dimensions	d ₁ :	9,0	mm
		d ₄ :	12,0	mm
		l:	37,0	mm
		a:	15,0	mm
		b:	19,0	mm
		d ₂ :	10,5	mm

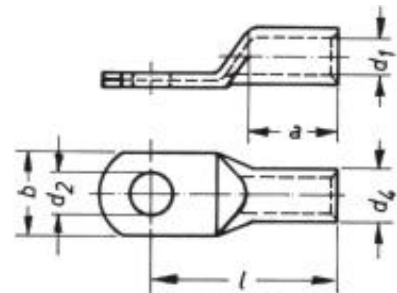

B: Material specification:

1 general

1.1 material
V4A (1.4571) (AISI 316 Ti)

2 condition

2.1 surface

2.1.1 smooth, brightly, evenly, no tears, scoring, folds, blisters, no other defects.