


EVT002

ADOGH040VAS0010E04

Connection technology

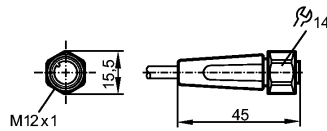

Product characteristics

Socket

For sensors with

M12 connector

Free from silicone

Gold-plated contacts

For hygienic and wet areas in the food industry

Electrical data

Electrical design		AC/DC
Operating voltage [V]		250 AC / 300 DC
Current rating [A]		4
Protection class		II

Environment

Ambient temperature [°C]		-25...100, cULus: max. 50 °C
Ambient temperature (moving) [°C]		5...100, cULus: max. 50 °C
Protection		IP 65 / IP 67 / IP 68 / IP 69K

Mechanical data

Design		straight
Material body		housing: PVC orange; sealing: EPDM
Material nut		stainless steel 316L / 1.4404
Tightening torque for knurled nut [Nm]		0.6...1.5
Weight [kg]		0.376



Electrical connection

Connection		PVC cable / 10 m; 4 x 0.34 mm ² (42 x Ø 0.1 mm); Ø 4.9 mm
Sheath colour		orange

Wiring

Core colours

 BK black
BN brown
BU blue
WH white

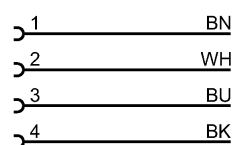

Remarks

Pack quantity	[piece]	1
---------------	---------	---