


DATASHEET



BTEVDALI

BT EVO 230V IP65 IK10 Adjustable Wattage and CCT DALI LED Bulkhead

www.mlaccessories.co.uk

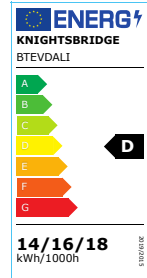

| MLA PART CODE | BTEVDALI |
|-------------------------------|--|
| DESCRIPTION | BT EVO 230V IP65 IK10 Adjustable Wattage and CCT DALI LED Bulkhead |
| NET WEIGHT (KG) | 0.8 |
| FINISH | White |
| DIFFUSER | Opal |
| DIMENSIONS (MM) | Diameter - 300 Projection - 65 |
| CONSTRUCTION | Construction - Polycarbonate Construction 2 - & ABS |
| CLASS | II |
| IP RATING | IP65 |
| IK RATING | IK10 |
| WATTAGE (W) | 14/16/18 |
| LAMP TECHNOLOGY | SMD LED |
| LUMENS (LM) | 1300/1400/1400,1500/1600/1500,1600/1800/1700 |
| LUMENS LIGHT SOURCE ONLY (LM) | 1700/1900/1800,1900/2100/2000,2100/2400/2200 |
| LUMEN TOLERANCE | 5% |
| EFFICACY (LM/W) | 140/138/136 |
| CIRCUIT WATTAGE (W) | 13.7/15.6/17.6 |
| CCT | 3000/4000/5700K |
| LIGHT COLOUR | CCT |
| CRI | >85 |
| SDCM | <6 |
| RUNNING CURRENT (A) | 0.071 |
| DISPLACEMENT FACTOR | >0.9 |
| SVM | 0.001 |
| PST-LM | 0.026 |
| BEAM ANGLE (DEGREES) | 130 |
| L70B50 LIFESPAN (HRS) | 50,000 |

| | |
|--|---|
| LED COMPATIBLE | Yes |
| DIMMABLE | DALI/PUSH DIM |
| DIFFUSER RATING | TP(b) |
| OPERATING TEMPERATURE | -20~40°C |
| INPUT VOLTAGE | 230V 50Hz |
| DRIVER | DRIVER TYPE - Constant Current MAX. OUTPUT - 20W OUTPUT VOLTAGE - 9-42V OUTPUT CURRENT - 350/400/450mA POWER FACTOR - 0.9 EFFICIENCY FULL LOAD - 86 ISOLATION - SELV AMBIENT TEMPERATURE (Ta) - -20~45°C CASE TEMPERATURE (Tc) - 85°C |
| STANDBY POWER | 0.25W |
| WARRANTY | 5year(s) |
| MANUFACTURED IN ACCORDANCE WITH | BS 60598 |
| ORIGIN OF MANUFACTURE | China |
| DECLARATION OF CONFORMITY (HELD ON FILE) | Yes |
| EAN | 5061061276785 |

Date Created: 16/07/2025 08:24

