


# Grey Elastic Rubber Trolley Wheel 80mm, 100kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **58-416-080R12**

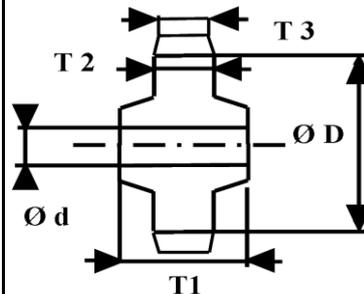

## Product Details

Wheel Rim : very thick black polyamide.  
Tyre : solid, grey bonded elastic rubber tyre, non marking.  
Hub : symmetrical, roller bearing.

## Specifications

Wheel Diameter - ØD ± 1%	<b>80 mm</b>
Hub Type	<b>Roller Bearing</b>
Hub Length T1	<b>45 mm ±1</b>
Width of Tread T2	<b>34 mm ±1</b>
Width of Tread-on floor T3	<b>34 mm ±1</b>
Axle Hole Ø d	<b>Ø 12 mm</b>
Hardness of tread A ±4	<b>A 70 Shore</b>
Load capacity	<b>100 Kg</b>
Temperature	<b>-20 / +60 °C</b>
Weight	<b>0,22 Kg</b>

TECHNICAL DATA

## Applications :

Sensitive materials handling on uneven surfaces.  
Resilient with a low starting effort.  
Does not leave scratches or other marks on surfaces.  
Reduces shock and vibration.  
Quiet in use and high wear resistance.  
Suitable for industrial floors and also all interior floors.