


PHE L150HUB

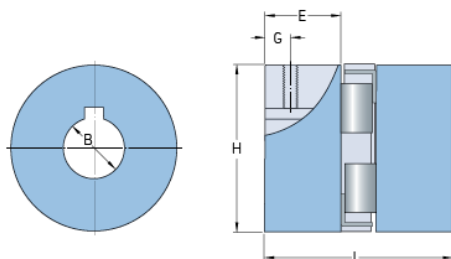

Tamaño	150
Posición orificio roscado G (mm)	22
Position threaded hole G (in)	0.87
Diámetro exterior H (mm)	96
Outer diameter H (in)	3.78
Orificio max	48
Maximum bore (in)	-
Tornillo de fijación	M10
Longitud E (mm)	45
Length E (in)	1.77
Orificio	15
Bore (in)	0.59