

Code marker cards SES-MARKERS®
with strips SPOT-IT
for printed circuits boards



SES-MARKERS®
Quality TEV




SPOT-IT

Material: TEV vinyl covered cotton
Temperature range: -30 to +105°C (class A)
 -40 to +150°C (short duration)
Operating temperature: +10 to +40°C
Adhesive: special thermal setting adhesive
Adherence on steel: 2,5 N/cm
Tensile strength at break: 80 N/cm

Dimensions of the strip: 2,45 x 4,75 mm
Dimensions of the card: 255 x 48 mm
Strip thickness: 0,30 mm
Standard colours: white - blue - green - yellow - red
Pack: 10 cards same legend (for smaller quantities an extra charge will be applied).

Specification: used for the location on printed circuits.

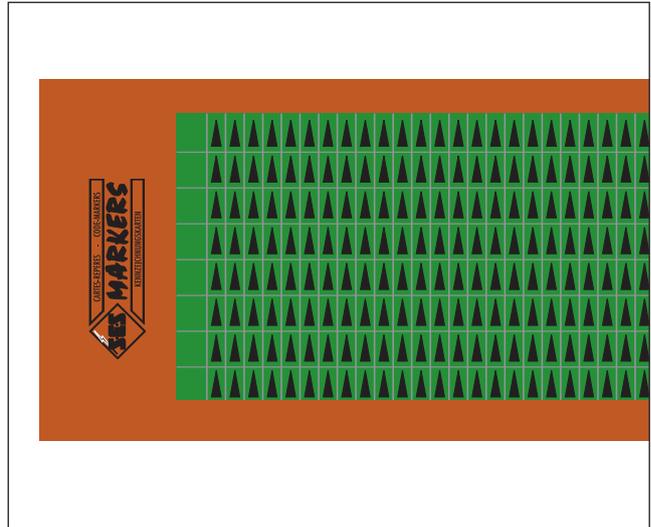

type	article number	strip colour	quantity strips/card	
S 5/01	0301 0200 001	white	752	10
S 5/02	0301 0200 002	blue	752	10
S 5/03	0301 0200 003	green	752	10
S 5/04	0301 0200 004	yellow	752	10
S 5/07	0301 0200 007	red	752	10

