

Features

- Well suited for work in confined spaces.
- Clamping width: 6~100mm
- Clamping depth: 70 /85mm

RS PRO SCISSORS TYPE PULLER 6~100MM

0286442



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *Adjustable scissor jaws for various clamping width and depth.*
- *For removing bearings, gears, sprockets in hard-to-reach spaces.*
- *Particularly suitable for industry, agriculture and DIY.*
- *The scissor design makes jaws grip automatically.*
- *Scissor joint increases clamping force when pulling.*


General Specifications

Operation	Gear
Maximum Load	1.5T (Tonnes)
Puller Type	Bearing Puller
Clamping Width	6-100mm
Clamping Depth	70 / 85mm
Drive (Hex)	13mm
Spindle size	M13 X 135mm
Number of legs	2
Weight	0.46 Kg

Crossed Jaw



Uncrossed Jaw

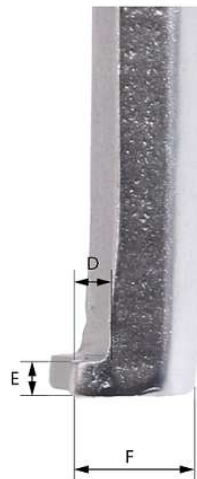

A	B	C	D	E	F
6~100mm	H13x135mm	23mm	4.5mm	2.5mm	8.5mm