



Scheda tecnica prodotto

LUHR 20



Gruppo di guida assiale senza tenute

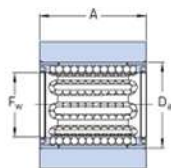

LUHR
With double lip seal

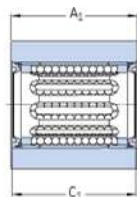

LUHR
With shaft seals

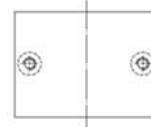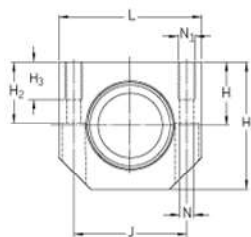

A [mm]:	30
D = Da [mm]:	28
Fw [mm]:	20
H [mm]:	23
H1 [mm]:	45
H2 [mm]:	22
H3 [mm]:	13
J [mm]:	40
L [mm]:	53
N [mm]:	5.3
N1:	M6
Ranghi sfere [#]:	6
Cdyn [N]:	1160

Data: 21/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

Scheda tecnica prodotto

LUHR 20

Gruppo di guida assiale senza tenute

C0 [N]:	800
Massa [kg]:	0.14
A1[mm]:	39
C1[mm]:	38

Data: 21/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.