



Datasheet

Stock No: 748-2355

ENGLISH

# RS Pro Black/Grey Equipment Wire, 0.22 mm<sup>2</sup> CSA, 1000 V 24 AWG, 100m




**BS 4808**

## Cable Construction

<b>Conductor</b>	<b>Tinned Copper</b>
square(mm <sup>2</sup> )	0.22
Construction	T0.20±0.008×7
Standard Dia.(mm)	0.60
<b>Insulation</b>	<b>PVC</b>
Thickness	0.3
Insulation Dia.(±0.1mm)	1.20

## Design

---

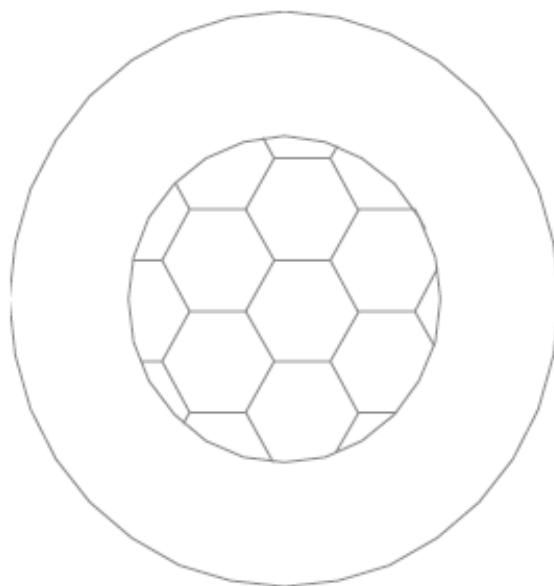

### Electrical Characteristics

Max.Conductor DC Resistance at 20 °C ( $\Omega$ /Km)	<86.2
Min.Insulation DC Resistance at 20 °C ( $M\Omega$ *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000