


Leitz IQ OptiMax Small Office 350 Micro Cut Paper Shredder Security P5 22L - White

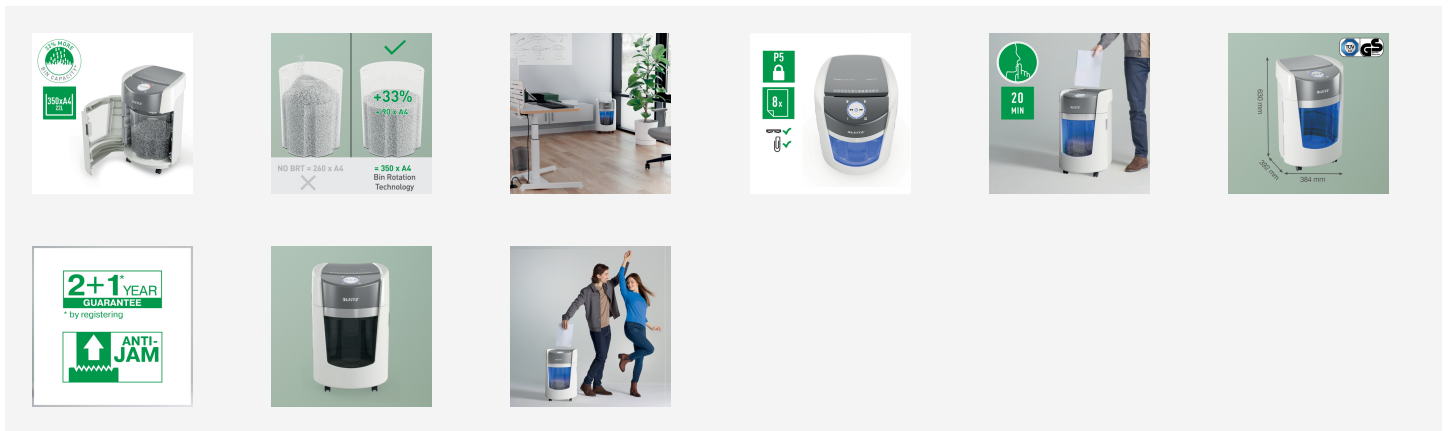

The Leitz IQ OptiMax small office shredder delivers an innovative, stylish shredding solution designed to provide exceptional document security and peace of mind. This high-security DIN P5 paper shredder effortlessly shreds up to 8x A4 sheets at a time into micro-cut pieces, making it the perfect small shredder for personal and office use. Featuring unique Bin Rotation Technology (BRT), effectively maximising bin capacity by +33%*. The rotating bin ensures flat, even paper distribution, preventing peaks from forming and allowing an additional 90x A4 sheets to be shredded before emptying. Thanks to BRT, there's no need to shake or remove the bin manually — the 'bin full' indicator activates only at 100% capacity. With a generous 22L bin that holds up to 350 x A4 sheets, this shredding machine ensures fewer interruptions. The illuminated blue bin and intuitive LED rotating display provide clear, easy-to-follow alerts such as bin full and door open, keeping shredding simple and efficient. Engineered for modern workspaces, the Leitz IQ OptiMax 350 office shredder is designed specifically for small offices, with ultra-quiet operation that minimizes noise — ideal for shared environments. Its sleek, compact circular design fits easily into tight spaces, blending seamlessly into any office setup. With a 20-minute continuous runtime, this reliable shredding machine ensures seamless document disposal whenever needed. White colour.

*Leitz IQ OptiMax 350 tested with and without bin rotation technology.



Attributes

- Shreds up to 8x sheets of A4 paper (80gsm) in just 8 seconds, into high security P5 micro cut pieces.
- Unique Bin Rotation Technology (BRT) maximizes bin capacity +33%* and significantly reduces mess when emptying.
*Leitz IQ OptiMax 350 tested with and without bin rotation technology.
- Generous 22L bin capacity holds up to 350x A4 sheets before it needs to be emptied; +33% more capacity compared to no BRT (+90 x A4 sheets).
- Intuitive LED rotating display with warning indications for bin full, door open, overheat and overload.
- Ultra quiet operation - for a calm working environment (when using Leitz oil papers regularly)
- Effortlessly shreds staples and paper clips, no need to remove them first.
- Continuous 20-minute run time, perfect for demanding office use.
- Anti-jam technology means that the shredder automatically stops and reverses the paper out when too much paper is inserted.
- The space-saving circular design fits neatly into corners and tight spaces to maximize your office area.
- Easy to move across locations thanks to four high quality castor wheels.
- 2+1 years guarantee - register to get your extra year

Specifications

Number	83591000
Colour	white
Dimensions (W x H x D)	384 x 630 x 392 mm
Cut Type	Micro Cut
Maximum Slot Entry Width (mm)	223
Run Time From Cold (min)	20
Run Time/Cool Down Time (min)	60
Shredded Particle Width mm	2x15
Security Level	P-5
Cutting Capacity sheets (80gsm paper)	8
Container/collection volume in l	22
Shreds	Staples and paper clips
Period of Warranty (Years)	2 + 1 year
Shredder Maintenance	Oil Sheets
Shredder Bin	Bin Window, Unique Filling Technology, Revolving, Backlit
Shredder Features	Wheels, Jam Free Technology, Touch Control
Weight	14000 g
Pallet quantity	8
EAN code	4002432142477