

FEATURES

- Trickle charger for NiMH/NiCd cells
- Charges 1- 4 AA, AAA, C or D cells and 1-2 9V Blocks
- 230Vac Input
- Test function for inserted cells
- Discharge function
- LED indicator confirms cell insertion
- Wrong polarity protection (mechanical)

RS PRO NiCd, NiMH 9V, AA, AAA, C, D Battery Charger with UKplug

RS Stock No.: 536-489



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS Pro multiple battery charger is a trickle charger and gives you the power to recharge various battery sizes. There is also the capability to charge or discharge up to 5 different cell sizes.

General Specifications

Number of Batteries Charged	6
Chemistries Charged	NiCd; NiMH
Battery Sizes Charged	9V; AA; AAA; C; D
Batteries Included	No
Car Lighter Adaptor	No
Case Material	ABS

Electrical Specifications

Input Voltage	230V AC \pm 10%, 50Hz
Plug Type	EU; UK
Input Lead Length	1.8m

Output Data	
Charge Current	120mA
Charging Time	13 to 27 h (9 V), 15 to 33 h (AA), 26 to 116 h (D), 26 to 52 h (C), 3 to 13 h (AAA)

Mechanical Specifications

Dimensions	198mm x 105mm x 52mm
Weight	480g

Operation Environment Specifications

Operating Temperature	0°C to +25°C
Storage Temperature	-25°C to 70°C

Protection Category



IP Rating	IP20
-----------	------

Approvals

Compliance/Certifications	CE
---------------------------	----



Technical Drawings:

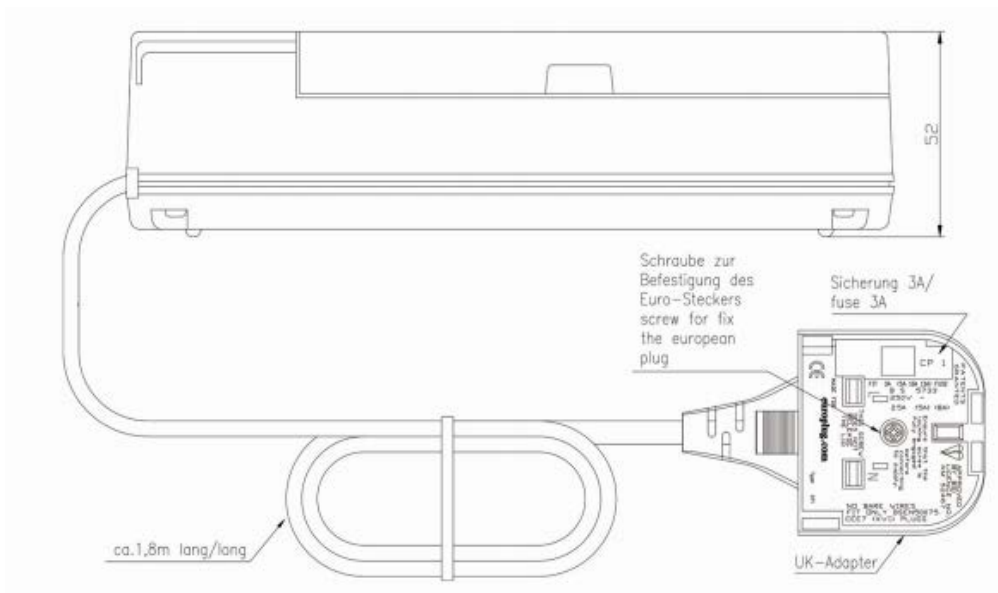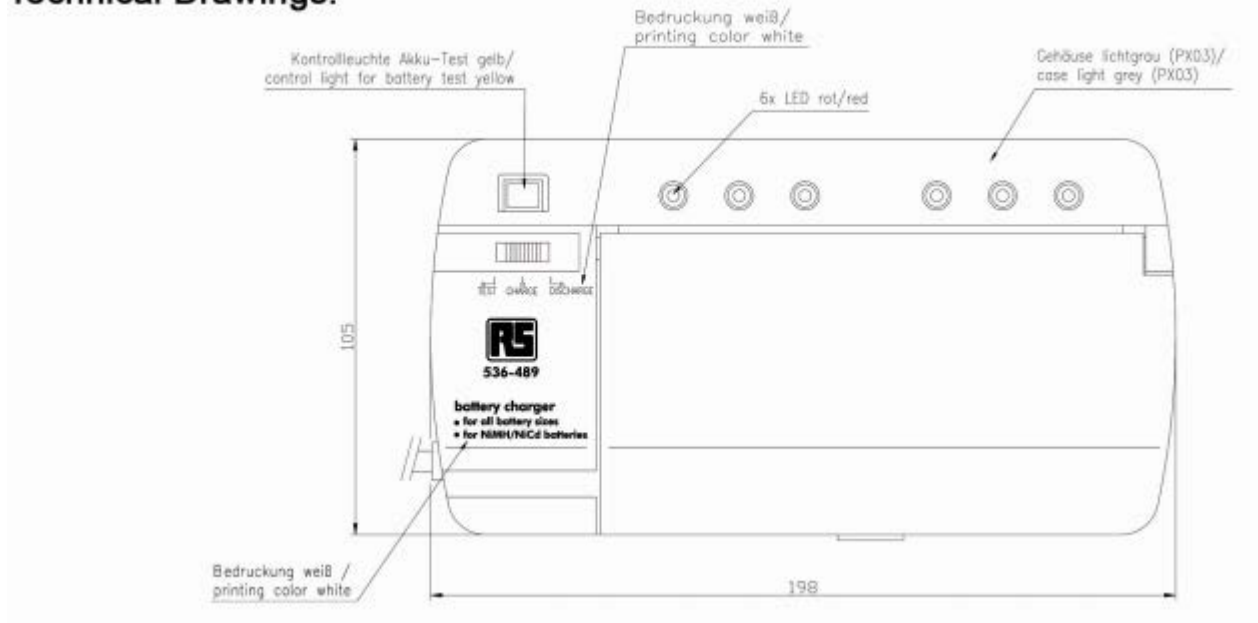

Battery Size	Charging Current (mA)	Charging Time (per 100mAh battery capacity)
AAA (Micro)	120	1h 10min
AA (Mignon)		
C (Baby)		
D (Mono)		
9V Block (E Block)	23	10h 45min