


Features

- A thicker, dual layer foam anti-fatigue mat for maximum levels of comfort.
- The new wear resistant top surface provides additional resilience against wear and tear.
- Insulates against cold concrete floors.
- Best suited to dry environments.
- Checkerplate surface provides attractive appearance.
- Ideal for demanding environments where regular turning is involved.
- Fire tested to: BS EN 13501-1 Class Cfl – s1.

RS PRO Orthomat Black/Yellow borders 0.9m x 1.5m

RS Stock No.: 0726321

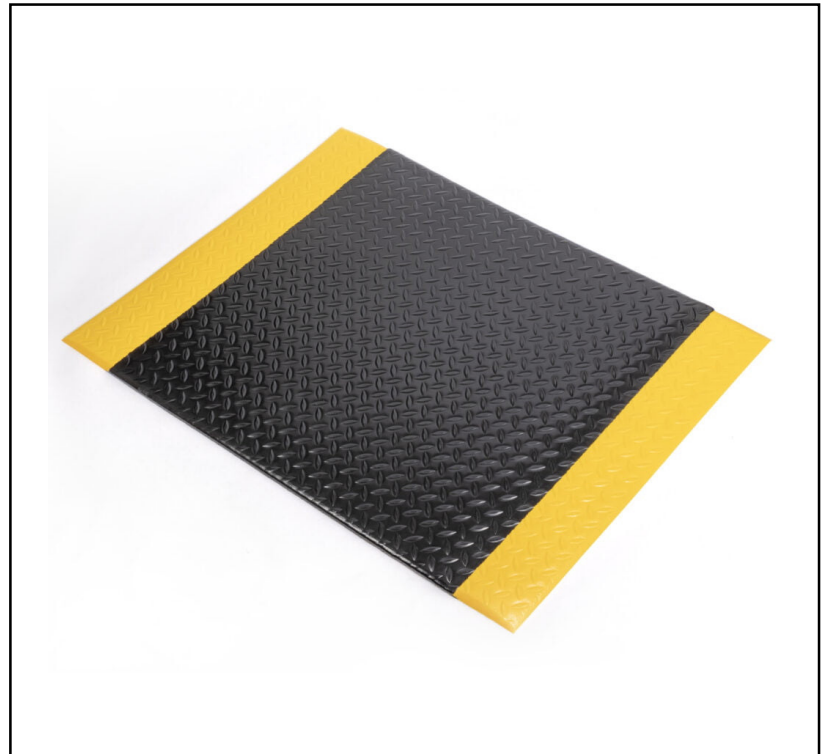

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- These mats are engineered to deliver superior cushioning and long-lasting durability in demanding workplace environments. Featuring a **thicker, dual-layer foam construction**, are specifically designed to reduce the strain and fatigue associated with prolonged standing on hard surfaces.
- Stands out as a premium solution among anti fatigue comfort mats thanks to its:
 - **Enhanced comfort** from the thicker foam layers that relieve pressure on joints and muscles.
 - **Improved safety**, with high-visibility yellow edges and a wear-resistant top surface.
 - **Thermal insulation**, protecting workers from cold floors and improving overall wellbeing.
 - **Stylish checkerplate finish**, combining aesthetics with functionality in professional settings.
- These **anti fatigue comfort mats** are especially ideal for dry workspaces where employees need extra support—such as manufacturing lines, packing stations, and inspection areas. Choose between **standard mats or continuous rolls** for coverage that fits your specific layout.

General Specifications

Size	0.9 m x 1.5 m
Product Height	15 mm
Colour	Black/Yellow
Weight (kg)	5.65
Material	Open Cell PVC foam
Surface Finish	Tough Checker plate surface
Min. Operating Temperature	0°C
Max. Operating Temperature	+60°C
Environmental Resistance	Suitable for dry indoor environments
Typical Applications	Production lines, Assembly areas, Packing stations, Workbenches
Installation Method	Loose lay
Cleaning Method	Brush/mop the top surface

Fire Tested to	BS EN 13501-1 Class Cfl - s1
-----------------------	------------------------------

Similar Products

Stock No.	Brand	Product Name	Size	Colour	Weight (kg)
0726320	RS PRO	Orthomat Comfort Plus	0.6 m x 0.9 m	Black/Yellow	2.25