

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0733910260](#)  
**Status:** **Active**  
**Overview:** SMA RF Connectors  
**Description:** 50 Ohms, SMA Jack, Bulkhead for RG-316 and RG-174 Cable, Brass Body, 0.25µm Gold (Au) Plated Contact, with Jam Nut and Lock Washer

**Documents:**

[3D Model](#) [Product Specification PS-89675-346-001 \(PDF\)](#)  
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**General**

Product Family RF/Coax Connectors  
 Series [73391](#)  
 Overview [SMA RF Connectors](#)  
 Product Name SMA  
 Style Cable  
 Type Subminiature  
 UPC 800756444024  
 Wire/Cable Type RG-174, RG-188, RG-316

**Physical**

Gender Jack  
 Keying to Mating Part None  
 Net Weight 3.445/g  
 Orientation Straight  
 PCB Mounting N/A  
 Packaging Type Bag  
 Panel Mount Yes  
 Panel Mount Method Bulkhead  
 Reverse Polar No

**Electrical**

Frequency 18 GHz  
 Impedance 50Ω  
 Power / Voltage VOLTAGE: 500 Vrms@Sea Level


**Solder Process Data**

Lead-freeProcess Capability N/A

**Material Info**

**Reference - Drawing Numbers**

Product Specification PS-89675-346-001  
 Sales Drawing SD-73391-026-000

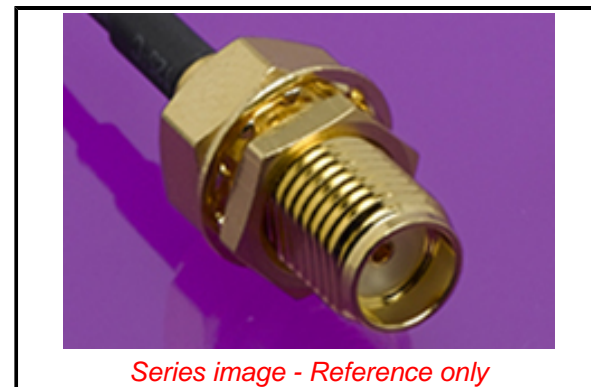

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2020)4578-DC (25 June 2020)  
 lead

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

**China RoHS**

ELV

50 Image

RoHS Phthalates

Not Relevant

Not Contained

**Search Parts in this Series**

[73391 Series](#)