

Datasheet

COMMSRAK adjustable shelf, 250mm deep

RS Stock number 529-003



COMMSRAK - Free standing

COMMSRAK

The COMMSRAK is a low cost easy to use 19" cabling frame in 12U, 37U & 42U.

Features

- Supplied in configured kit form
- 3 height options - 12U, 37U and 42U
- Open frame construction gives all round access
- Cable management provided in verticals
- Assembly tool included
- Load rating 150kg
- Wide range of IMRAK accessories - see accessories information table

Contents of kit

Item/Description	Material/Finish
1 COMMSRAK	1.6mm zintec steel, paint RAL 7035


Note: Order frame then floor or wall kit

Ordering information


Description	Order code
12U frame	52-255052B
37U frame	52-255051E
42U frame	52-255050H
Floor mount kit	52-255053K
Baying kit	52-244931C
Top cover 450mm	52-248074K
Type 1 earthing kit	52-248075G



42U floor mount COMMSRAK

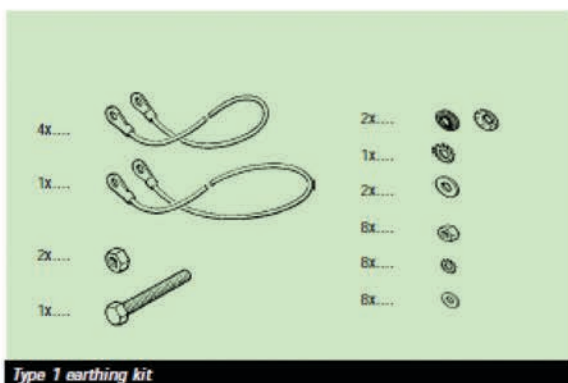

Type 1 earthing kit

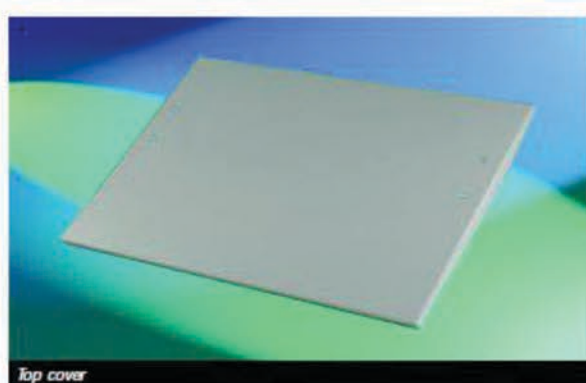

Top cover

19" CANTILEVER SHELVES

Cantilever shelves fix directly onto the standard 19" panel mounts. The shelves occupy 2U of panel mount height. Cantilever shelves have a nominal load rating of 20kg, mounted in the middle of the shelf.

Applications

Ideal for networking applications and modem mounting

Contents of kit

Description	Qty	Material/Finish
Cantilever shelf	1	1,6mm steel, painted RAL 7035
Fixings		

Ordering information

Description	Order code
255mm deep shelf	802-562284D
400mm deep shelf	802-562285B



255mm deep cantilever shelf



400mm deep cantilever shelf