


AxiMax 400 Comm Z5U, Ceramic, 0.1 uF, -20/+80%, 50 VDC, Z5U, AxiMax, Commercial Standard

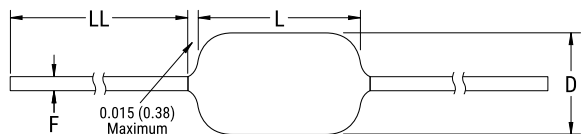

**Dimensions**

<b>D</b>	2.41mm MAX
<b>L</b>	4.32mm MAX
<b>LL</b>	25.4mm MIN
<b>F</b>	0.51mm +0.025/-0.076mm

**Packaging Specifications**

<b>Packaging:</b>	Bulk, Bag
<b>Packaging Quantity:</b>	300

**General Information**

<b>Supplier:</b>	KEMET
<b>Series:</b>	AxiMax 400 Comm Z5U
<b>Description:</b>	AxiMax, Commercial Standard
<b>RoHS:</b>	Yes
<b>Termination:</b>	Tin
<b>Failure Rate:</b>	N/A
<b>Halogen Free:</b>	Yes

**Specifications**

<b>Capacitance:</b>	0.1 uF
<b>Capacitance Tolerance:</b>	-20/+80%
<b>Voltage DC:</b>	50 VDC
<b>Dielectric Withstanding Voltage:</b>	125 VDC
<b>Temperature Range:</b>	-10/+85C
<b>Temperature Coefficient:</b>	Z5U
<b>Dissipation Factor:</b>	4% 25C
<b>Aging Rate:</b>	7% Loss/Decade Hour
<b>Insulation Resistance:</b>	1 GOhms