



ENGLISH

# Datasheet



 

## 8 way 3.81mm terminal block header

RS Stock number 790-0910



### Dimensions: (mm)

#### PCB Layout

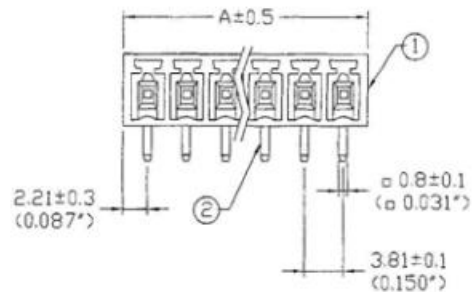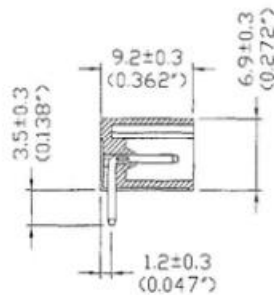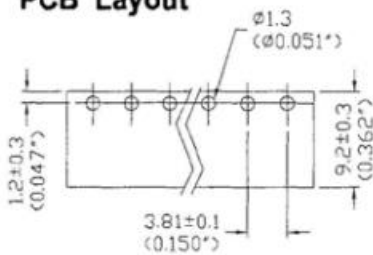



## Specifications

- Current Rating:12Amp AC300V
- Insulation withstands volts: AC2000V min
- Insulation resistance: > 2000 M  $\Omega$  DC500V
- Operation Temperature: -40°C to +105°C

## Material

- Insulating Body: Polyamide 66 (UL94V-0)
- Solder Pin: Brass

## Finish

- Solder Pin: Tin Plated
  
- RoHS Compliant

Pitch : 3.81mm(0.150inch)

Poles	A(mm)	A(inch)	Poles	A(mm)	A(inch)
2	8.23	0.324	15	57.76	2.274
3	12.04	0.474	16	61.57	2.424
4	15.85	0.624	17	65.38	2.574
5	19.66	0.774	18	69.19	2.724
6	23.47	0.924	19	73.00	2.874
7	27.28	1.074	20	76.81	3.024
8	31.09	1.224	21	80.62	3.174
9	34.90	1.374	22	84.43	3.324
10	38.71	1.524			
11	42.52	1.674			
12	46.33	1.824			
13	50.14	1.974			
14	53.95	2.124			