


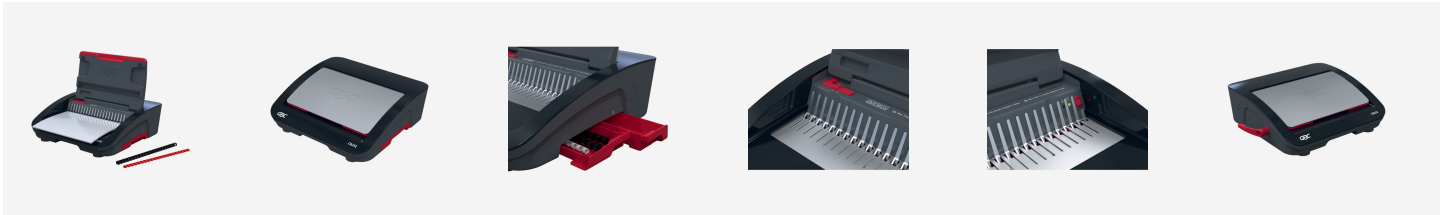

GBC CombBind® CB25E Electric Binding Machine

Enhance your office efficiency with the CombBind® CB25E, the ultimate electric comb binder designed for high-demand environments such as busy offices and educational settings. This robust machine streamlines the binding process, effortlessly punching through stacks of up to 25 sheets of 80gsm paper and securely binding up to 390 sheets at a time with 45mm spines. Its sleek, lightweight design ensures it can be easily transported and stored, making it the perfect addition to any workspace. The CB25E is engineered for user convenience, featuring an anti-jam overload LED indicator for a smooth, uninterrupted binding experience every time. Additionally, it includes a handy clippings tray and storage compartment for a tidy workspace. Black and silver colour.



Attributes

- Binds up to 390 A5/A4 sheets (80gsm) at a time using a 45mm comb.
- Punches up to 25 sheets at a time (80gsm)
- Versatile binding: easily bind A5 documents with A5 combs and A4 portrait pages with A4 combs.
- Electric punch for faster, effortless binding, saving you time and reducing manual effort.
- Side margin adjustment for precise alignment and consistent binding results.
- Fixed margin depth for consistent and high quality binding.
- Anti-jam overload LED for seamless and jam-free binding every time.
- Non-slip rubber feet for stable and secure placement.
- Convenient clippings tray and a built-in storage compartment for added organisation.
- Lightweight and compact design for easy portability and convenient storage.

Specifications

Number	4410064
Colour	black
Material	Plastic
Dimensions (W x H x D)	501 x 402 x 394 mm
For Format	A4/A5
Max. Binding Width (mm)	297
Operation Mode	Electric Punch
Max. Binding Capacity (70gsm paper)	390
Punch Capacity (70gsm paper)	28
Punch Capacity (80gsm paper)	25
Punch Capacity (Clear Film 0,2 mm)	2
No. of Punches	21
Electric punching	Yes
Spine size selector	No
Max. Comb Diameter (mm)	45
Waste tray	Yes
Suitable for	Comb Punch and Bind
Weight	10000 g
Packing unit	1
Pallet quantity	24
Minimum order quantity	1
EAN code	5028252644495