




# Datasheet

ENGLISH

## Threaded Ball and Spring Plunger

### Material

Burnished or stainless steel

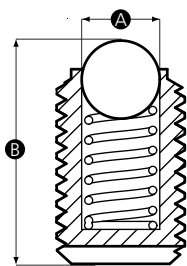

Part No.	A	B	Thread size	Body material
478652	1.5	8	M3	Burnished steel
478636	2.5	10	M4	Burnished steel
478668	3	13	M5	Burnished steel
478658	3.5	15	M6	Burnished steel
478731	5	18	M8	Burnished steel
478737	6	21	M10	Burnished steel
478747	8	25	M12	Burnished steel
478753	10	28	M16	Burnished steel
478664	12	35	M20	Burnished steel
478743	1.5	8	M3	Stainless steel
478567	2.5	10	M4	Stainless steel
478917	3	13	M5	Stainless steel
478927	3.5	15	M6	Stainless steel
478911	5	18	M8	Stainless steel
478573	6	21	M10	Stainless steel
478608	8	25	M12	Stainless steel
478563	10	28	M16	Stainless steel
478923	12	35	M20	Stainless steel