

Features

- Perfect for fitting and removing external circlips
- Phosphate finish providing strong corrosion protection
- PVC sleeves proving enhanced grip and control
- Chrome Vanadium Steel construction providing durability and long life
- Spring mechanism that assists with gripping circlips fitted externally

RS PRO 125mm Circlip Pliers

RS Stock No.: 541-6832



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Introducing external circlip pliers with bent tips from our trusted and reliable own brand RS PRO, a unique type of pliers used to install and remove external circlips from a range of appliances. These long-lasting RS PRO circlip pliers are made with a durable chrome vanadium steel that includes a phosphate finish, providing corrosion resistance properties and long life. The handles on the RS PRO circlip pliers include PVC coated sleeves for enhanced grip and control. The bent tips provide extra assistance when gripping circlips in awkward spaces and angles whilst making improving visibility for the user.

General Specifications


Plier Type	Circlip Pliers
Tip Style	Bent
Material	Chrome molybdenum steel for pliers, spring steel for automatic return function and vinyl dipping handles
Finish	Chemical black finish with polish main surface for pliers, red colour handle
Kit Content	1 pc - 5" (125 mm) external 90 bent type, small cylindrical tip circlip pliers with automatic return spring and red colour vinyl dipping grip
Applications	Vehicles, Bicycles, Blenders, Washing machines

Mechanical Specifications

Jaw Length	26mm
Overall Length	125mm
Diameter of Tip	0.9mm
Hardness	heat treated to HRC: 45~55 (circlip tip), HRC: 44~48 (handle) and HRC:30~48(joint)
Circlip Seal Ring Capacity	3mm to 10mm

Approvals

Compliance/Certifications	DIN A01
---------------------------	---------

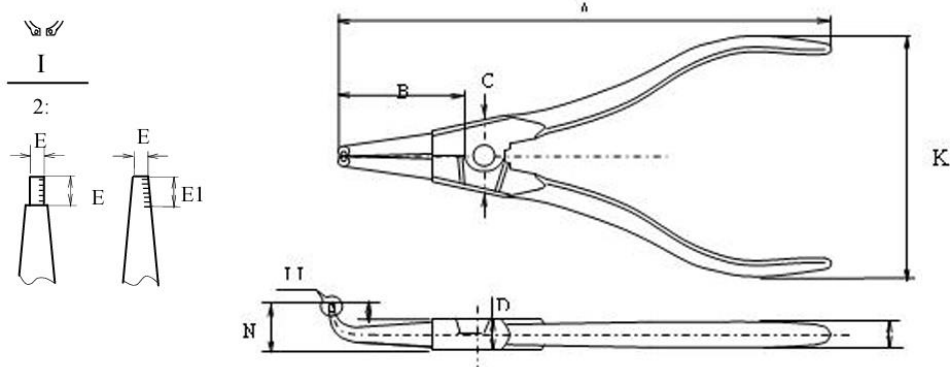

Inspection Item	Specification	Inspection tools
A mm	125 ± 2	Caliper
B mm	25.9 - 1	Caliper
C mm	(18)	Caliper
D mm	8.5 - 1	Caliper
E mm	0.9 - 0.2	Caliper
E1 mm	1.5 - 0.2	Caliper
K mm	70 +2-1	Caliper
N1 mm	13.5±2	Caliper

INSTRUCTION FOR USE / ADDITIONAL INFORMATION /
DIAGRAMS / ILLUSTRATIONS / ACCESSORIES