

# CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, light gray, halogen-free, comprising upper part and mounting base, width: 60 mm, height: 40 mm, length: 2000 mm

## Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

## Commercial data

Item number	3240352
Packing unit	20 pc
Minimum order quantity	20 pc
Sales key	BE7
Product key	BE7441
Catalog page	Page 579 (C-3-2019)
GTIN	4046356508377
Weight per piece (including packing)	855 g
Weight per piece (excluding packing)	740 g
Customs tariff number	39259020
Country of origin	DE

# CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>




## Technical data

### Product properties

Product type	Wiring duct
--------------	-------------

### Dimensions

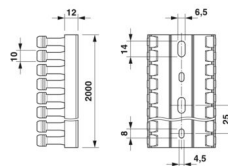Dimensional drawing	
Width	60 mm
Height	40 mm
Length	2000 mm

### Material specifications

Color	light gray (RAL 7035)
Material	PC/ABS
Flammability rating according to UL 94	V0
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1, HL 2, HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1, HL 2, HL 3
Components	halogen-free

### Cable/line

Halogen-free	yes
--------------	-----

### Mechanical properties

Usage cross-section	1948 mm <sup>2</sup> (100 %)
Number of cables at 60% filling volume	62 (2.5 mm <sup>2</sup> Ø 3.4 mm)

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 90 °C
---------------------------------	------------------

# CD-HF 60X40 - Cable duct


3240352

<https://www.phoenixcontact.com/in/products/3240352>



## Drawings

Dimensional drawing

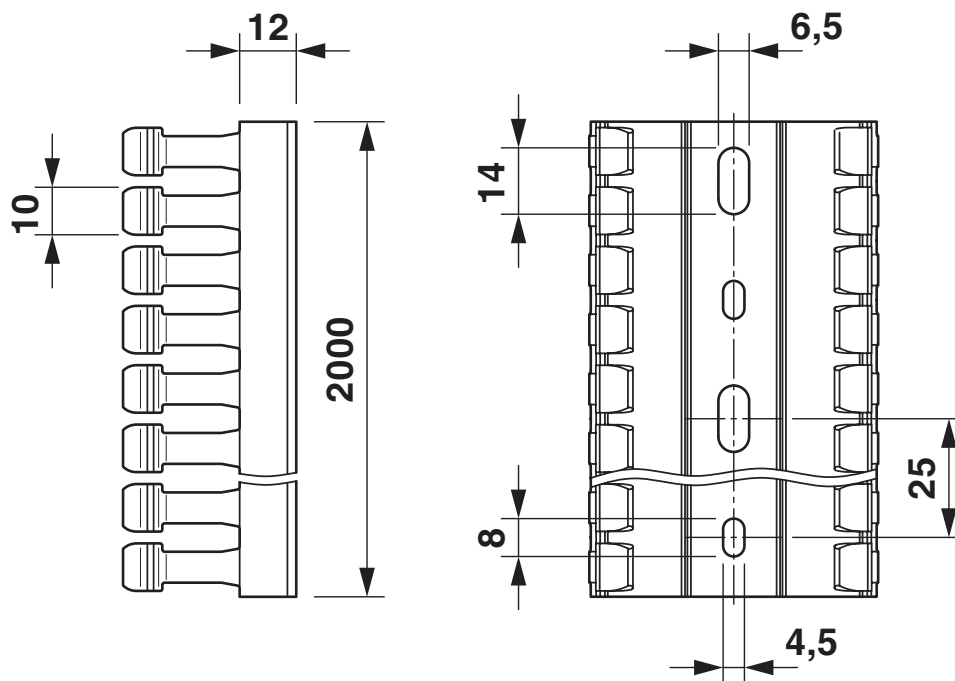

Base perforation according to DIN EN 50085

# CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/3240352>



**CSA**

Approval ID: 80202282



**VDE approval of drawings**

Approval ID: 40058453

**DNV**

Approval ID: TAE00004VN



**UL Recognized**

Approval ID: E328576

# CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## Classifications

### ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

### ETIM

ETIM 9.0	EC000012
----------	----------

### UNSPSC

UNSPSC 21.0	39131700
-------------	----------

# CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

# CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## Accessories

### CD-HF COVER 60 - Cover profile

3240372

<https://www.phoenixcontact.com/in/products/3240372>



Cover for cable duct, light gray, halogen-free, width: 60 mm, length: 2000 mm

---

### RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/in/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

## CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/in/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 2 ... 8 mm

---

## CD WR - Universal wire retaining clip

3240284

<https://www.phoenixcontact.com/in/products/3240284>



Universal wire holding bracket, perforated, for wiring channels



## CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/in/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

---

## UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/in/products/1212509>



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

## CD-HF 60X40 - Cable duct

3240352

<https://www.phoenixcontact.com/in/products/3240352>



## PPS CD M - Cable duct cutter

1207569

<https://www.phoenixcontact.com/in/products/1207569>



Cable duct cutter, for burr-free cutting cable ducts and their covers, can be used up to a width of 125 mm

---

## CUTFOX-CD - Cable duct cutter

1212474

<https://www.phoenixcontact.com/in/products/1212474>



Cable duct cutter, for cutting plastic cable ducts, covers, and profiles, 45° limit stop also for bevel cuts, 75 mm cutting length

---

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.  
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420  
[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)