



## Bracket 30/60



- Profile finishing: not required






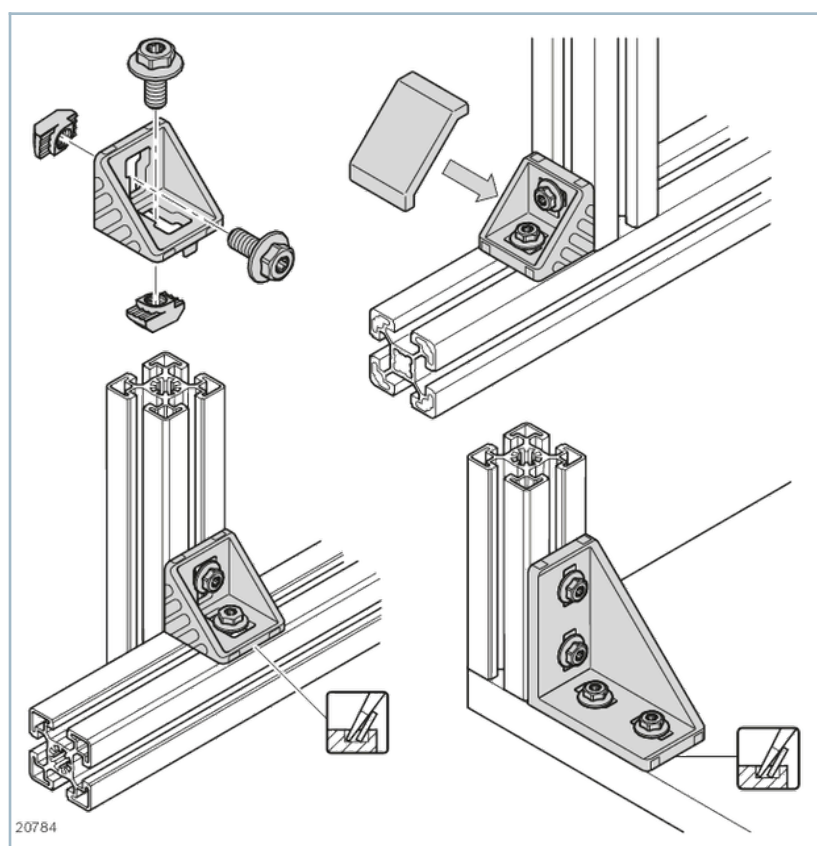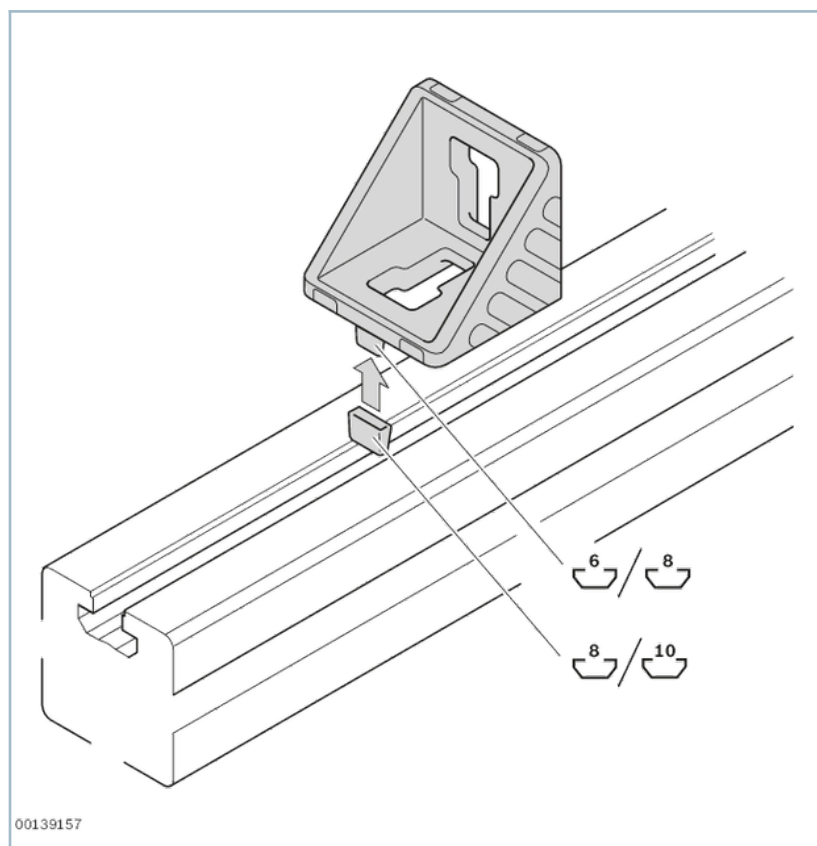

- Brackets with centering lugs for rapid, precise assembly with protection against turning
- Centering lugs can be easily broken off for assembly on plates or at right angles to the slot
- Version *designLINE* with special silver paint (RAL 9006) for an especially high-quality design
- Intermediate element for positioning brackets in the next largest slot
- Cover cap to protect from dirt, available in signal gray (RAL 7004) and black ESD (RAL 9005)


# Product description

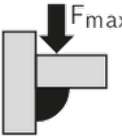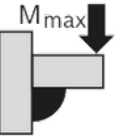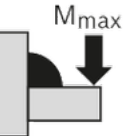


Connection elements, selection criteria

# Technical data

	Groove	ES D	Material entry			
				$F_{\max}$	$M_{\max}$	$M_{\max}$
				N	Nm	Nm
Bracket	8		Bracket: Diecast aluminum, vibratory ground Fastening material: steel; galvanized	2500	100	170
	8		Bracket <i>designLINE</i> : Diecast aluminum; vibratory ground, painted (RAL 9006) Fastening material: steel; galvanized	2500	100	170
	8		Bracket: Diecast aluminum, vibratory ground	2500	100	170
Cover cap for bracket			PP			
			PP			
Intermediate element for 10 mm slot	8; 10		PA; black			

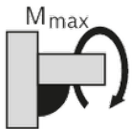





$M_{\max}$
Nm
25
25
25

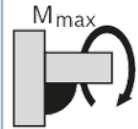

M<sub>max</sub>

Nm

Typ

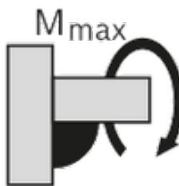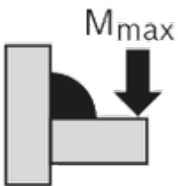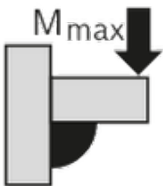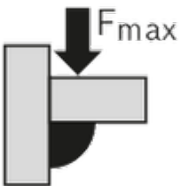

30 / 60

2500 N


100 Nm

170 Nm

25 Nm

Dimensions

Bracket 30/60 with cover cap

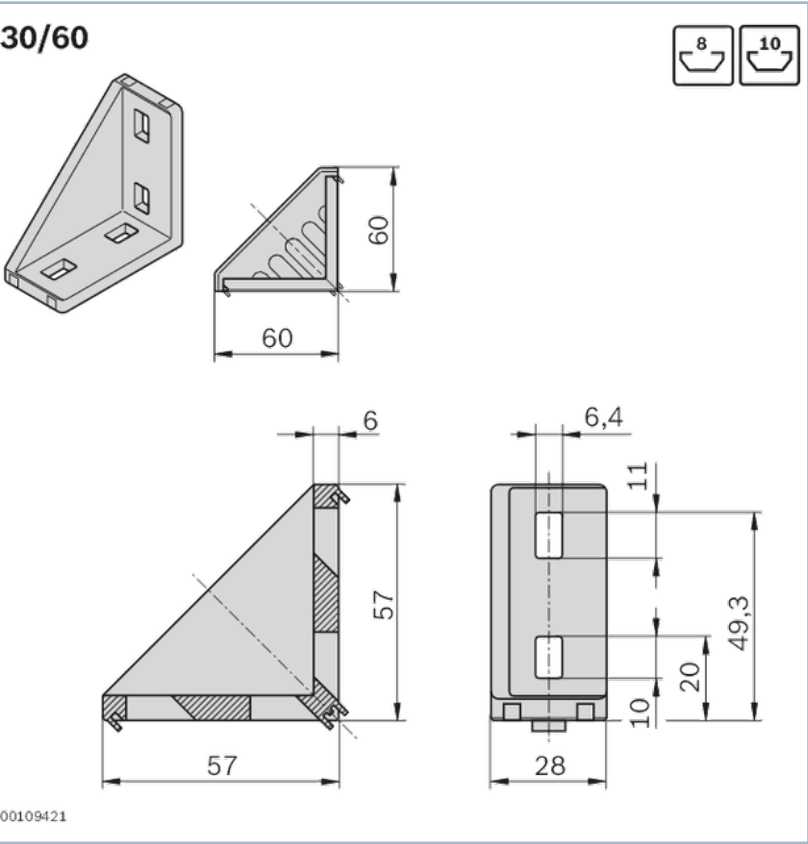

## Accessories

### Recommended accessories


Intermediate element for 10 mm slot

Cover cap for bracket 30/60, signal gray

Cover cap for bracket 30/60, black

## Delivery notes

FS2

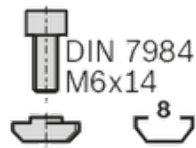

## Ordering codes

	Groove	ESD	No.
Bracket 30x60 set (standard) N8/8	8		3842523541
Bracket 30x60 set <i>designLINE</i> , N8/8	8		3842551601
Bracket (standard) 30x60	8		3842523538
Cover cap for bracket 30/60, signal gray			3842548848
Cover cap for bracket 30/60, black			3842548849
Intermediate element for 10 mm slot	8; 10		3842523537