

RSC24AXL/8
Mobile roller cab with 8 drawers, with anti-tilt system, long model

Long model with 8 fully extractable drawers (882x367 mm), with ball bearing slides:

- 6 drawers, 70 mm high
- 2 drawers, 140 mm high

 88 kg


Features:

- New ABS reinforced worktop with anti-fall edges, eight holes for accommodating screwdrivers and 6 tote trays
- Sturdy nylon front, with built-in label holder
- Drawer bases protected by foamed rubber mats
- 4 castors, Ø 125: 2 fixed and 2 steering (one with brake)
- Front centralized safety lock
- Static load capacity: 1,000 kg
- Built-in side bottle holder (can be applied on both sides)
- Each drawer can accommodate up to 6 EVA foam or ABS thermoformed trays

Available accessories:

- Wood worktop 2400 RSC24/PL
- Document holder 2400 RSC24//PD-A
- Paper roll holder 2400 RSC24/PC-A

Worktop can support portable tool chests RSC22, RSC23, RSC23C and RSC23T.

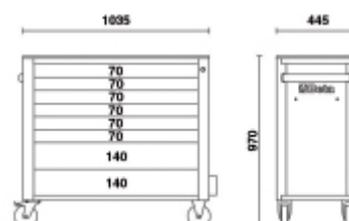

|  | art. |  | |
|---|--------------|---|-----------------|
| 024004281 | RSC24AXL/8-O |  | RAL 2011 - 7016 |
| 024004283 | RSC24AXL/8-R |  | RAL 3000 - 7016 |
| 024004287 | RSC24AXL/8-A |  | RAL 7016 |