

# Bocube

Enclosures, polycarbonate UL 94 V0, single-coloured



B 261706 PC-V0 7035

Order no.: 96016325

\* = Available on request.

## Characteristics

Colour of enclosure group

Light grey, similar to RAL 7035

Colour of enclosure group

Light grey

Protection class

IP 66, 68 - 1,2m (2 hours)

Enclosure Material

ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C)

PU seal, foamed; for details please see Technical Information

Scope of delivery

Lid and base, hinged quick-release catches

## Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

## Technical documentation / Downloads

### Technical drawings

3D product data in STEP format: Registration necessary

Product drawing in PDF format: 96016325 B-261706-PC-V0-7035.pdf (234.9 KB)

### Product information

Bocube GB.pdf (1.9 MB)


Highlights Bocube.pdf (3.8 MB)

## Dimensions

Dimensions

271 x 170 x 60 mm

Product drawing

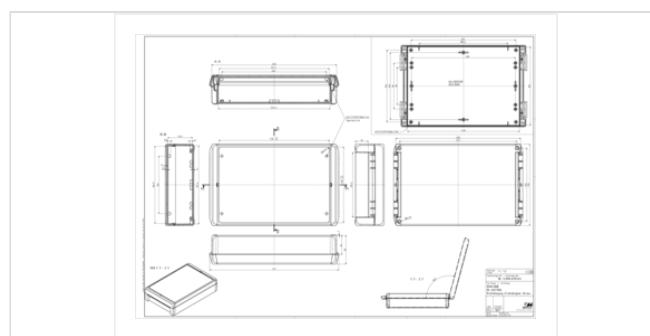

Product drawing in DXF format: 96016325 B-261706-PC-V0-7035.dxf (3.9 MB)

Drawing for mechanical processing: 96016325 B-261706-PC-V0-7035-G.dxf (3.0 MB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

## Works Test Certificates

688 WPZ-Bocube-PC-V0 DE.pdf (184.6 KB)

689 WPZ-Bocube-ABS DE.pdf (165.1 KB)

689 WPZ-Bocube-ABS EN.pdf (160.3 KB)

688 WPZ-Bocube-PC-V0 EN.pdf (179.1 KB)

## Matching accessories

---



### Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS

96310300	B SC 17 PC-V0 3000	For B 2617..	Flame red
96310302	B SC 17 PC-V0 5002	For B 2617..	Ultramarine blue
96310309	B SC 17 PC-V0 6029	For B 2617..	Mint green
96310304	B SC 17 PC-V0 7024	For B 2617..	Graphite grey
96310305	B SC 17 PC-V0 7035	For B 2617..	Light grey
96310303	B SC 17 PC-V0 1023	For B 2617..	Traffic yellow



### Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

96910300	B SC HB 17 PC-V0 3000	For B 2617..	Flame red
96910302	B SC HB 17 PC-V0 5002	For B 2617..	Ultramarine blue
96910309	B SC HB 17 PC-V0 6029	For B 2617..	Mint green
96910304*	B SC HB 17 PC-V0 7024	For B 2617..	Graphite grey
*			
96910305*	B SC HB 17 PC-V0 7035	For B 2617..	Light grey
*			
96910303	B SC HB 17 PC-V0 1023	For B 2617..	Traffic yellow



### Wall brackets

96510005	B WL 7035	For B 08... - B 26...	Light grey
96510004	B WL 7024	For B 08... - B 26...	Graphite grey



### Mounting panels, laminated paper, 2 mm

96606300	B M 2617	For B 2617..	
----------	----------	--------------	--



### Front panels, 2 mm, natural-coloured anodised aluminium

96706300	B FP 2617	For B 2617.., front panel thickness 2.5 mm	
----------	-----------	--	--



#### Sets of screws

96300000	B SHR	D (for optional screwing of enclosures B 0808 - 2617)
96600010	B M-SHR	C (for fixing mounting panels B M 1008-2736)
96700000	B FP-SHR	A (for fixing front panels)



#### Distance bolts

96726000	DIBLZ AK 30x7/IM3/26	ND = 2.4 - 2.6, for B...06 if a mounting plate is used
96728000	DIBLZ AK 30x5/IM3/28	ND = 2.4 - 2.6, for B...06



#### Blanking plugs to determine the hinge side

96410000	B VS 3000	Flame red
96410005	B VS 7035	Light grey
96410004	B VS 7024	Graphite grey



#### DIN rail acc. to DIN EN 60715 TH 15

22152301	TS 15	For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)
----------	-------	---



#### DIN rail acc. to DIN EN 60715 G 32

22322301	TS 32	For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)
----------	-------	---



#### DIN rail acc. to DIN EN 60715 TH 35

22352301	TS 35	For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)
----------	-------	---



#### Pressure compensation membrane DAE

52011000	DAE-D11	Self-adhesive membrane $\varnothing$ 11 mm
----------	---------	--



#### Screws (SHR) and distance bolts (DIBLZ) for mounting bosses in plastic enclosures

59006217	SHR Z KA30x8	SD = 3,0 / ND = 2,4-2,6 / KD = 6,0
----------	--------------	------------------------------------