






Category	Commercial Panels
Application	Ancillary, Commercial, Education, Healthcare, Retail
Specification	Performance

Endurance UGR<19 600x600

Endurance TP(a) UGR<19 600x600 Panel Cool White

Code: AERMLED3/60/CW

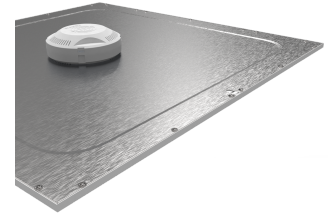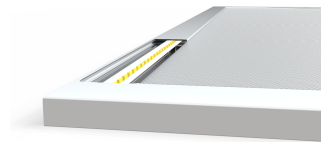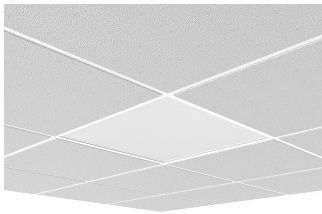

PRODUCT FEATURES

- Edge lit LED panel suitable for education, commercial and ancillary area applications
- Cool white, warm white and daylight options
- TPa as standard
- Compatible with either the self-test panel pod or the sensor pod
- UGR<19 (unified glare rating) compliant luminaire assisting to eliminate glare for visual comfort
- White anodised aluminium frame for visual compatibility with ceiling grid
- Surface mounting frame option

GENERAL INFORMATION

Wattage	31W
Lumens Delivered	3600lm
Lm/W	113lm/W
Beam Angle	80
CRI	80
CCT	4000K
Input	220-240V
Operating Temp	-20? to 40?
SDCM	4
UGR	17
Product Weight without Packaging	2.1 kg

TECHNICAL INFORMATION

Light Source	LED
Colour / Finish	White
IP Rating	IP44
IK Rating	IK02
Class Protection	2
Internal / External	Internal
Surface / Recessed / Suspended	Ceiling, Recessed, Suspended
Lumen Depreciation	L80 76,000h
Warranty (Years)	5
CE Mark	Yes
Height	10 mm
Accessories	AERMLED/SK, AERMLED/60/SMF, AERMLED/60/CGCB/KIT, APRK/60





Category	Commercial Panels
Application	Ancillary, Commercial, Education, Healthcare, Retail
Specification	Performance

Endurance UGR<19 600x600

Endurance TP(α) UGR<19 600x600 Panel Cool White

Code: AERMLED3/60/CW

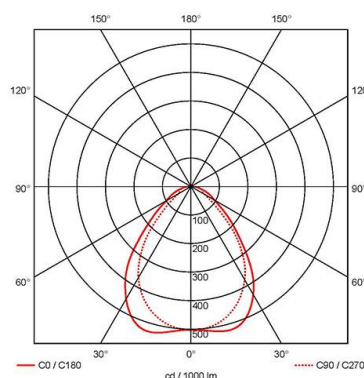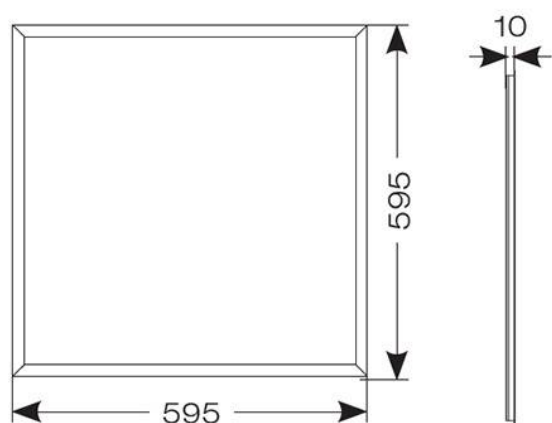

ACCESSORIES

APOD/1/3NM/DA	Panel Pod PRO DALI
AERMLED/SK	Endurance Panel Suspension Kit
ASMF60/I	Surface Mounting Frame 600x600
AERMLED/60/CGCB/KIT	Endurance 600x600 Concealed Grid Ceiling Kit
APRK/60	600x600 Plasterboard Recessed Kit
AARX60K/I	ARX 600x600 Anti-Ligature Kit
ASRF/60/I	600x600 Skylight Recessed Frame
ADDIM/30/MC	Multi-current Dimmable Driver 30W