

ALPHA

3470BOG100P30-13

EAN 4031582413410

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole. Wheel made of heat resisting synthetic material, self-lubricating bushing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	100 mm
Wheel width	35 mm
Centre hole	13 mm
Offset	40 mm
Swivel Interference	180 mm
Overall height	128 mm
Temperature	- 40 / + 280 °C
Standard	EN_12532
Weight	0.689 kg
Swivel Radius	90 mm
Hardness of tread	Shore D 90
Load capacity	125 kg
Load capacity (static)	250 kg

Dimensions

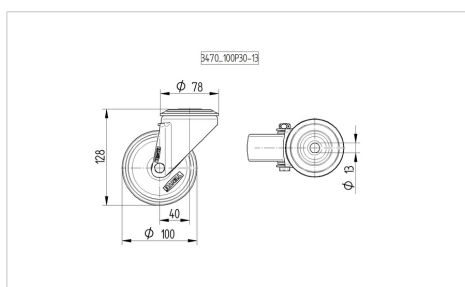

Advantages at a glance

Roll performance	● ● ● ● ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ● ●