




Product Datasheet

**RS- 1806845**

**Premier Safety Lockout Padlock  
Long Body with Steel Shackle - Key Different  
ES - PLSP 7 - S - KD - Green**

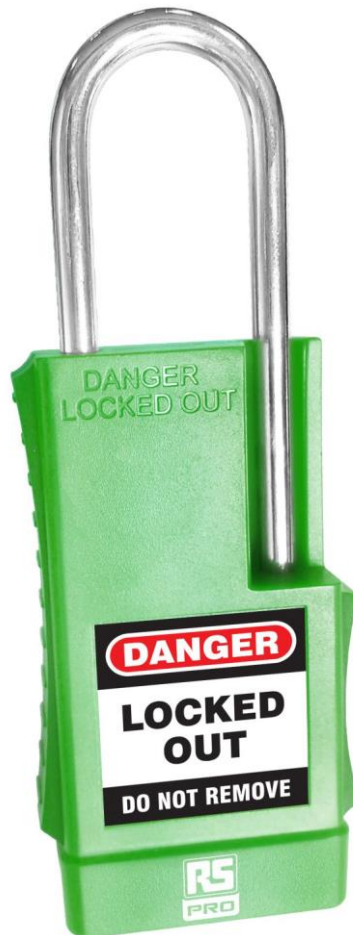

*RS, Professionally Approved Products, gives you professional quality parts across all products categories. Our range has been testified by engineers as giving comparable quality to that of the leading brands without paying a premium price.*

Standard features:



- Each padlock is supplied with 1 key.
- Chrome plated steel Shackle for better corrosive resistance of 5 mm for best physical strength
- Resistant to extreme temperature changes – 13<sup>0</sup> F to + 194<sup>0</sup> F.
- Compact for easy carrying and storage.
- Light weight, solid Aluminium core Safety Padlock
- Made especially for Lockout / Tagout Applications
- Automatic locking for user convenience
- 6 pin brass cylinder
- Insulated body, resistant against heat, dust and debris.
- Compliant with regulations : 1 employee = 1 padlock = 1 key (OSHA).
- Logo printing / Laser engraving optional (front, back, left and right side).
- Key retaining feature (when shackle is open).
- The solid aluminum body is encased by a colored plastic cover for easy identification. To further improve visibility and identification,
- Long Body insulated against electric shock

### **Technical data**

- Comes with 5 mm thick x 41 mm steel shackle.
- Weight around : 113 grams
- Specified for Lockout / Tagout purpose internationally

### **Package includes:**

- Packed single unit in cardboard box.