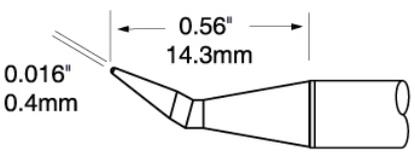
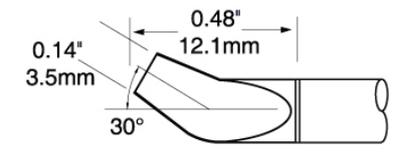


 
 
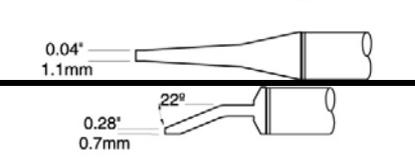
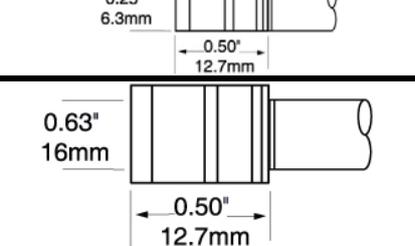
PTC Cartridges are compatible with MX-500, MX-5000, MX-5200 and CV-5200 Systems –MX-PTZ and CV-H4-PTZ Hand pieces

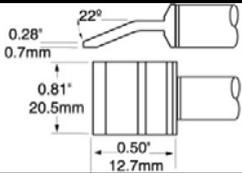
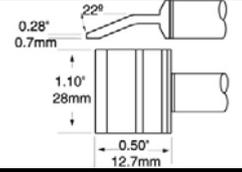
 
PTTC Cartridges are compatible with MX-500, MX-5000 and MX-5200 Systems – MX-PTZ Hand piece.

Temperature	PTC	PTTC	Application
675°F/357°C	PTC-6	PTTC-0	Temperature Sensitive
775°F/413°C	PTC-7	PTTC-1	Most Standard
875°F/468°C	PTC-8		Ceramic and High Thermal Demand
925°F/496°C	PTC-9	PTTC-8	

Please note the above temperatures are the maximum temperatures of the heater. The idle temperature is dependent on the geometry of the cartridge (up to 15°C lower.)

Bent			
	PTC-6CN1404A PTC-7CN1404A PTC-8CN1404A PTC-9CN1404A	PTTC-001B PTTC-101B PTTC-801B	Bent 30° 0.4mm x 14.3mm (0.016" x 0.56")
	PTC-6FB1235R PTC-7FB1235R PTC-8FB1235R PTC-9FB1235R	PTTC-008B PTTC-108B PTTC-808B	Bent 30° 3.2mm x 12.1mm (0.14" x 0.48")

Blade			
	PTC-6CH1713A PTC-7CH1713A PTC-8CH1713A PTC-9CH1713A	PTTC-002 PTTC-102 PTTC-802	Blade 1.27mm x 16.55mm (0.05" x 0.65")
	PTC-6CH1720A PTC-7CH1720A PTC-8CH1720A PTC-9CH1720A	PTTC-003 PTTC-103 PTTC-803	Blade 2mm x 16.5mm (0.08" x 0.65")
	PTC-6BL1306R PTC-7BL1306R PTC-8BL1306R PTC-9BL1306R	PTTC-004 PTTC-104 PTTC-804	Blade 6.35mm x 12.7mm(0.25" x 0.5")
	PTC-6BL1316R PTC-7BL1316R PTC-8BL1316R PTC-9BL1316R	PTTC-005 PTTC-105 PTTC-805	Blade 15.75mm x 12.7mm(0.63" x 0.5")

Blade			
	PTC-6BL1321R PTC-7BL1321R PTC-8BL1321R PTC-9BL1321R	PTTC-006 PTTC-106 PTTC-806	Blade 20.6mm x 12.7mm (0.81" x 0.5")
	PTC-6BL1328R PTC-7BL1328R PTC-8BL1328R PTC-9BL1328R	PTTC-007 PTTC-107 PTTC-807	Blade 28mm x 12.7mm (1.1" x 0.05")
Conical			
	PTC-6CN2304A PTC-7CN2304A PTC-8CN2304A PTC-9CN2304A	PTTC-001 PTTC-101 PTTC-801	Conical 0.4mm x 19mm (0.016"x0.7")