


# 27" CABINET FOAM TOOL KIT 217 PIECES RED

ITEM ID: TCMME217K

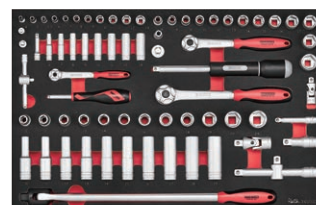

- 217-piece tool kit in a 27" Classic roller cabinet (TCW707K)
- Tools organised in precision-cut, three-colour EVA foam inlays across four drawers
- 1/4", 3/8", and 1/2" square drive sizes with 72-teeth ratchets
- Regular and deep metric sockets (4 mm to 24 mm)
- Includes extension bars, universal joints, drive adaptors, combination spanners, adjustable wrenches, and curved jaw power grip plier
- General-purpose tools: hammers, measuring tools, chisels, punches, utility knife, and hacksaw
- Full screwdriver set with 1/4" ratcheting bits driver and extensive bit selection
- Ball point hex keys (metric and AF) and TX keys
- Heavy-gauge steel roller cabinet with red powder-coated finish
- Seven fully extendable drawers with 30 kg capacity each
- Heavy-duty 5" x 2" castors (two fixed, two braked swivel) and metal side handle
- Integrated key lock
- Compatible with TengTools Tool Control System

# 27" CABINET FOAM TOOL KIT 217 PIECES RED

ITEM ID: TCMME217K

·	"27" Cabinet FOAM Tool Kit 217 Pieces Red	·	1/2" Breaker Bar 450 mm DIN3122
·	27" Cabinet 7 Drawers Red	·	1/4" Ratchet 72 Teeth
·	Screwdriver Set Mixed FOAM4X4 114 Pieces	·	3/8" Ratchet 72 Teeth
·	Ball Point Hex Key AF	·	1/2" Extension Bar 63.5 mm
·	3/8 5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16,	·	1/2" Extension Bar 150 mm
·	Ball Point Hex Key Metric	·	1/2" Universal Joint
·	1.5, 2, 2.5, 3, 4, 5, 6, 7, 8, 10	·	Reducing Adaptor 1/2" F - 3/8" M
·	TX Key	·	1/2" Socket 6 pt Metric
·	TX8, TX9, TX10, TX15, TX20, TX25, TX27,	·	10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 22, 24
·	TX30, TX40	·	1/2" Deep Socket 12 pt Metric
·	1/4" Flat Bits 25 mm	·	10, 11, 12, 13, 14, 15, 16, 17, 18, 19
·	0.6×3.5, 0.6×4.5, 0.8×4.0 (×2), 0.8×5.5,	·	1/4" Spinner Handle
·	1.0×5.5 (×3), 1.2×6.5, 1.4×7.0, 1.6×8.0	·	1/4" Extension Bar 50 mm
·	1/4" PH G Bits 25 mm PH2G	·	1/4" Extension Bar 100 mm
·	1/4" Hex Bits 25 mm	·	1/4" Universal Joint
·	2, 3, 4, 5, 6, 8	·	1/4" Magnetic pick up socket
·	Hex Socket Adaptor 1/4" Hex - 1/4" 25 mm	·	1/4" Socket 6 pt Metric
·	Hex Socket Adaptor 1/4" Hex - 1/4" 30 mm	·	4, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13
·	1/4" Bit Adaptor Hex Bit Coupler	·	1/4" Deep Socket 6 pt Metric
·	Side Cutting Plier 160 mm	·	6, 7, 8, 9, 10, 11, 12, 13
·	Heavy Duty Combination Plier 185 mm	·	3/8" Wobble Extension Bar 75 mm
·	Long Nose Plier 200 mm	·	3/8" Universal Joint
·	Quick Set Water Pump Plier HRC60 250 mm	·	Reducing Adaptor 3/8" F - 1/4" M
·	Flat Screwdriver	·	Step Up Adaptor 3/8" F - 1/2" M
·	0.5×3.0, 1.0×5.5, 1.2×6.5	·	3/8" Bit Adaptor Hex bit coupler 1/4" Hex
·	PH Screwdriver	·	3/8" Socket 6 pt Metric
·	PH0, PH1, PH2	·	8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 22
·	PZ Screwdriver PZ2 × 100 mm L Hex Shaft	·	3/8" Rotating Spinner Handle
·	1/4" Ratcheting Bits Driver Set	·	Spanner Set FOAM4X4 15 Pieces
·	1/4" Flat Bits 25 mm	·	Adjustable Wrench 150 mm
·	1.0×5.5, 1.4×7.0	·	Adjustable Wrench 250 mm
·	Hex Socket Adaptor 1/4" Hex - 1/4" 25	·	Curved Jaw Power Grip Plier 235 mm
·	mm	·	Combination Spanner Metric
·	1/4" PH Bits 25 mm	·	8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19
·	PH1, PH2	·	General Tool Set FOAM4X4 15 Pieces
·	1/4" PZ Bits 25 mm	·	Hacksaw 24TPI Metal
·	PZ1, PZ2	·	Utility Knife
·	1/4" PH Bits 25 mm	·	Flat Cold Chisel
·	PH1 (×4), PH2 (×4), PH3 (×3)	·	18, 25
·	1/4" PZ Bits 25 mm	·	Centre Punch 5 mm
·	PZ1 (×4), PZ2 (×4), PZ3 (×3)	·	Ball Pein Hammer 24oz
·	1/4" ROB Bits 25 mm	·	Soft Face Hammer
·	1, 2, 3	·	Measuring Tape Metric/Inch 3m
·	1/4" TPX Bits 25 mm	·	Parallel Pin Punch
·	TPX10, TPX15, TPX20 (×2), TPX25 (×2),	·	3, 4, 5, 6, 7, 8
·	TPX27, TPX30, TPX40	·	Steel Rule mm/AF 200 mm"
·	1/4" Bits Driver Extension 100 mm		
·	1/4" Bits Driver Extension 150 mm Flexible		
·	1/4" TX Bits 25 mm		
·	TX6, TX7, TX8, TX9, TX10, TX15, TX20		
·	(×3), TX25 (×3), TX27, TX30, TX40		
·	1/4", 3/8" & 1/2" Socket Set FOAM4X4 73 Pieces		
·	1/2" Ratchet 72 Teeth		