

**Product selected: Capsule 12V/50W LP**

Low pressure, low voltage (12V) halogen capsule lamps offer compact size, high performance and low internal pressure making them ideal for use in open luminaires without any need for additional protection.

**Applications**

- Interior display, shop window, restaurant and discotheque lighting
- Precision task lighting

**Features**

- Compact size for optimum luminaire design
- Dimmable using a suitable dimmer for operation with a transformer
- Constant light output throughout lamp life
- The use of UV-Stop materials dramatically reduces UV emissions
- Average rated life: 2000 hours

**Directions for use**

- Suitable for use in open luminaires following the new Luminaire Standard EN 60598


**Product Attributes**

Item description	Capsule 12V/50W LP
Ordering Code	0021022
EAN code	5410288210223
Packing Quantity	50
Wattage (W)	50
Voltage (V)	12
Cap	GY 6.35
Max. Over. Length (mm)	44
Diameter (mm)	12
Light output (lm)	900
Colour Temp (K)	2900
Average life (hours)	1500

**Product Image**



**Line Drawing**

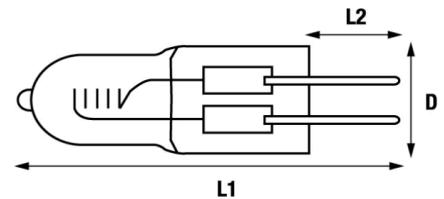

**UV Stop**



**Lamp Cap**

**GY6.35**

