



Technical data

51101

One direction thrust ball bearings

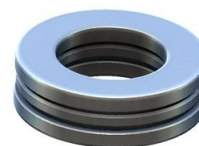

VISUAL (S)

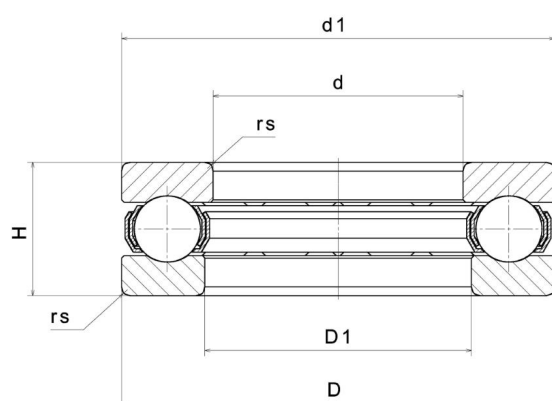

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	12 mm
D - External diameter	26 mm
T - Thrust bearing height	9 mm
rs - Min fillet radius	0,3 mm
Mass	0,023 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	10300000 mN
C0a - Static axial load rating	15400000 mN
Cua - Limit axial load rating	695000 mN
N lim - Oil lubrication limit speed	55200 °/s
N lim - Grease lubrication limit speed	38400 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	18 mm
da min - Min shoulder diameter IR	20 mm

