

# EH 22,5-FP/ABS-PC GY7035 - Filler plug



1071139  
<https://www.phoenixcontact.com/gb/products/1071139>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



DIN rail housing, Filler plug for unoccupied terminal points (tall design), width: 21.35 mm, height: 19.65 mm, depth: 13.67 mm, color: light gray (similar RAL 7035)

## Your advantages

- DIN rail or panel mounting for application-specific device attachment
- Easy design-in, thanks to variable housing form factor
- Complete flexibility, thanks to PCBs with horizontal, frontal, and orthogonal orientation to the front of the device
- Three cover versions for individual PCB connections
- Integration of a wide variety of PCB connection technologies for a functional device design

## Commercial data

Item number	1071139
Packing unit	50 pc
Minimum order quantity	50 pc
Sales key	ACHCHC
Product key	ACHCHC
GTIN	4055626751481
Weight per piece (including packing)	2.108 g
Weight per piece (excluding packing)	1.998 g
Customs tariff number	85389099
Country of origin	IN

## Technical data


### Notes

Assembly note	Please observe the application note in the download area.
---------------	---

### Product properties

Product type	Filler plug
Housing type	DIN rail housing
Housing series	EH
Product family	EH..ABS-PC..
Type	Filler plug for unoccupied terminal points (tall design)
Ventilation openings present	no

### Dimensions

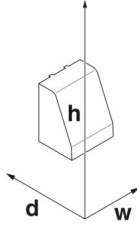Dimensional drawing	
Width	21.35 mm
Height	19.65 mm
Depth	13.67 mm

### Material specifications

Color (Housing)	light gray (RAL 7035)
Flammability rating according to UL 94	V0
Housing material	ABS-PC
Surface characteristics	untreated

### Environmental and real-life conditions

#### Ambient conditions

Max. IP code to attain	IP20
Ambient temperature (operation)	-40 °C ... 80 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 80 °C
Relative humidity (storage/transport)	95 %

### PCB data

Type of PCB mount	Slot
-------------------	------

# EH 22,5-FP/ABS-PC GY7035 - Filler plug



1071139


<https://www.phoenixcontact.com/gb/products/1071139>

## Mounting

Mounting type	Latching with upper housing part
---------------	----------------------------------

## Drawings

Dimensional drawing

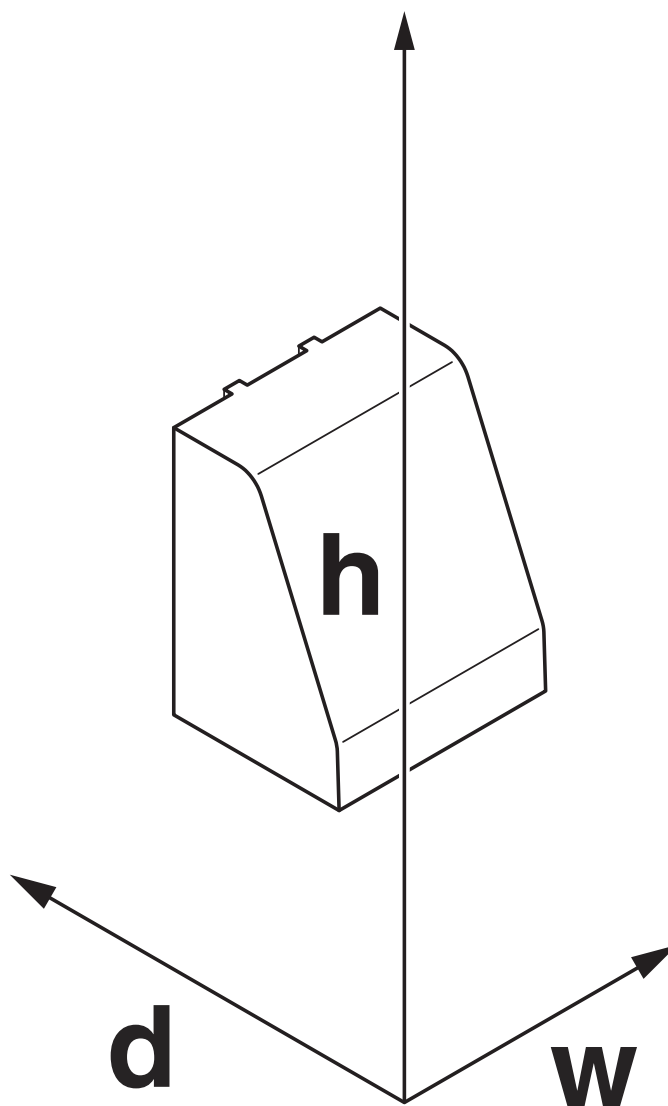

Schematic figure for illustrating the item dimensions. The figure is not of the desired product. For further details, refer to the product drawings in the "Downloads" tab.

# EH 22,5-FP/ABS-PC GY7035 - Filler plug



1071139

<https://www.phoenixcontact.com/gb/products/1071139>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/gb/products/1071139>



**UL Recognized**

Approval ID: E240868

# EH 22,5-FP/ABS-PC GY7035 - Filler plug



1071139

<https://www.phoenixcontact.com/gb/products/1071139>

## Classifications

### ECLASS

ECLASS-13.0	27190605
-------------	----------

### ETIM

ETIM 9.0	EC002779
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# EH 22,5-FP/ABS-PC GY7035 - Filler plug



1071139

<https://www.phoenixcontact.com/gb/products/1071139>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)