


AS-Interface illuminated pushbutton module

AS-i Module 2BI 2LO WT/WT

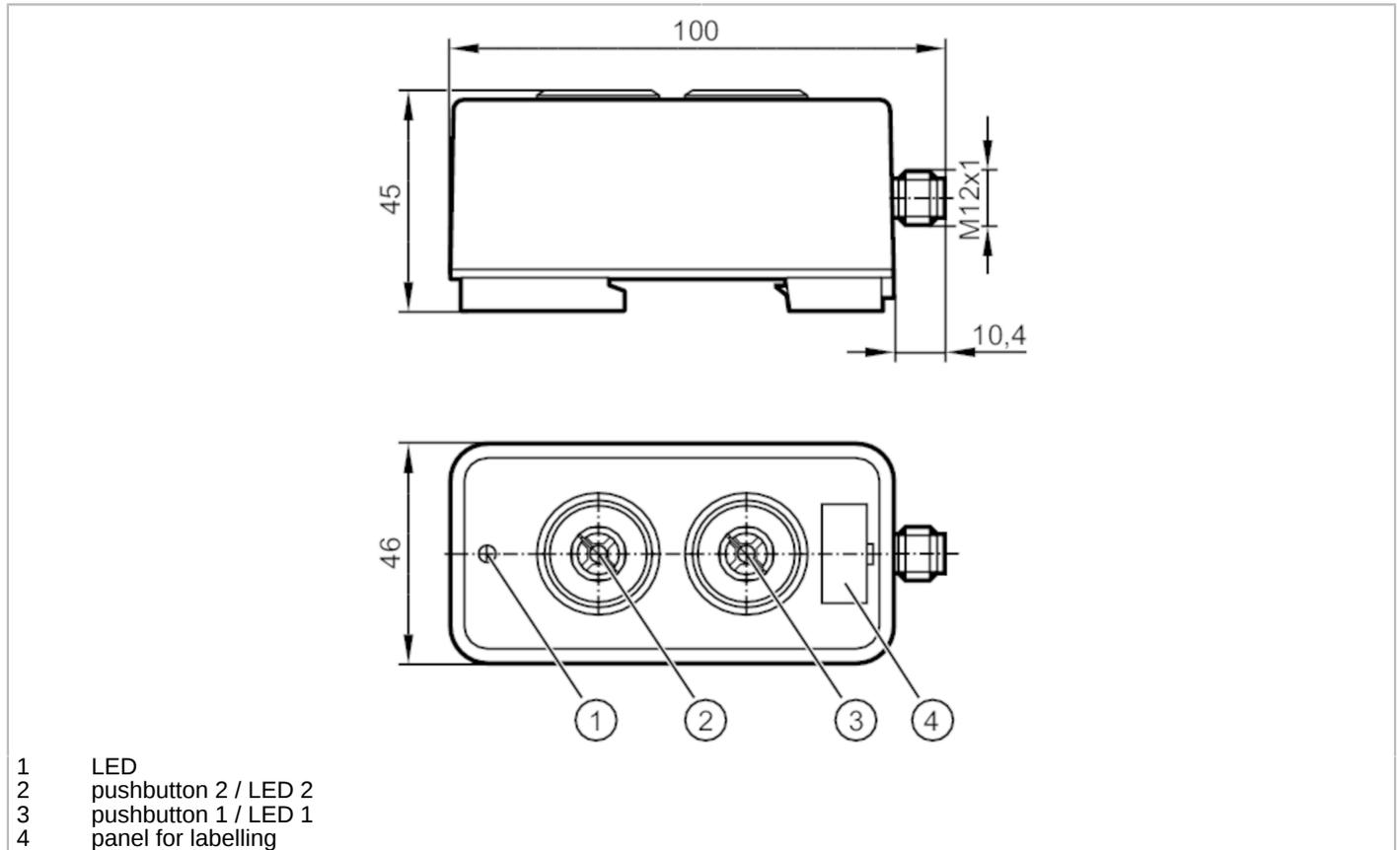

Application	
Design	Colour inserts changeable
Application	field installation
Electrical data	
Operating voltage [V]	26.5...31.6 DC
Max. current consumption from AS-i [mA]	55
Inputs	
Sensor supply of the inputs	AS-i
Operating conditions	
Ambient temperature [°C]	-25...60
Storage temperature [°C]	-40...85
Protection	IP 67
Tests / approvals	
EMC	EN 61000-6-2 EN 62026-2
AS-i classification	
AS-i version	2.11; 3.0
Extended addressing mode	yes
AS-i master profile	M2; M3; M4

AC2386



AS-Interface illuminated pushbutton module

AS-i Module 2BI 2LO WT/WT

AS-i profile	S-7.A.E				
AS-i I/O configuration [hex]	7				
AS-i ID code [hex]	A.E				
AS-i certificate	133801				
Assignment of the data bits	data bit	D0	D1	D2	D3
	LED 1	DO-0	-	-	-
	LED 2	-	DO-1	-	-
	pushbutton 1	DI-0	-	-	-
	pushbutton 2	-	DI-1	-	-

Mechanical data

Weight [g]	140
Housing	housing for DIN rail mounting
Type of mounting	mounting on DIN rail
Dimensions [mm]	100 x 46 x 45
Materials	PA

Displays / operating elements

Display	operation	LED, green
	errors	LED, red
Operating elements	2	freely programmable backlit function keys

Electrical connection

Module connection	M12
-------------------	-----


Accessories

Items supplied	cover support: 2
	colour inserts: 2, red
	2, green
	2, yellow
	2, blue
	2, white

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

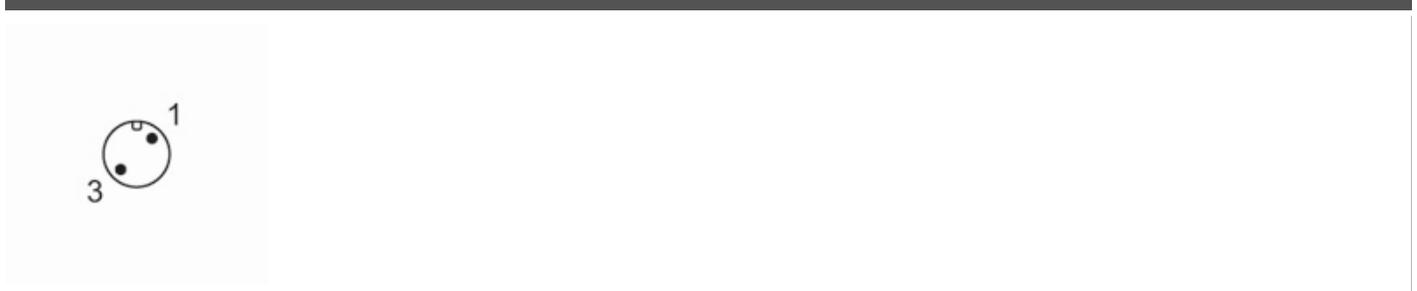

1	AS-i +
3	AS-i -