



PSHEY35-XL-N [↗](#)

Plummer block housing unit

Plummer block housing units PSHEY, cast iron housing, radial insert ball bearing with grub screws in inner ring, P seals

X-life

Technical information

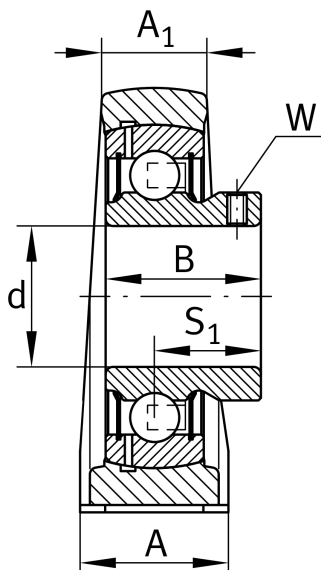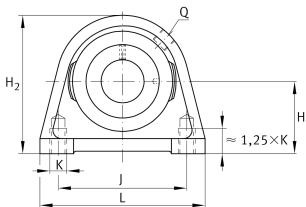

Your current product variant

Groove	N	Cast iron housing with undercut slot for end caps
Material	GG	Grey cast iron

Main Dimensions & Performance Data

d	35 mm	Bore diameter
L	103 mm	Length total
H 2	93 mm	Height
≈m	1.2 kg	Weight

Mounting dimensions

J	82.6 mm	Distance fixing bore
K	M10	Thread fixing bore

Dimensions

H	47.6 mm	Distance shaft axis
A	45 mm	Width (base)
A 1	27 mm	Width (head)
Q	M6	Connection thread for lubrication
B	34.95 mm	Width of inner ring
S 1	25.45 mm	Distance of raceway to locking collar



Additional information

SHE07	Housing
GAY35-XL-NPP-B	Bearing designation
KASK07	Protecting cap

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.