

Optional Parts


Wall Mount Bracket

- **Avoid Potential Trouble when moving machinery!**
- **Easily removable connection! (Wiring unplugs along with it!)**
- **Easy to disconnect when needing repair!**

BEFORE...



AFTER...

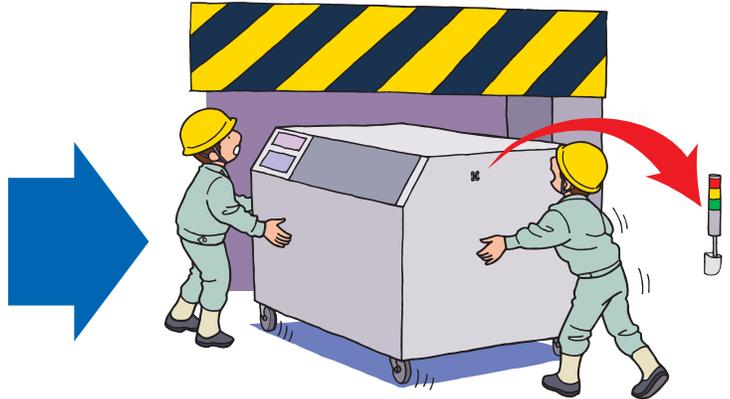

Easy steps to installing the bracket



Drill the holes on the machine to attach the mounting connector and bracket.



Fix the mounting parts onto the machine with the proper hardware.



Join the connectors together.





Hook the mounting bracket onto the metal tabs and attach it with the screws.

SZ-020 (For $\phi 21.7\text{mm}$ Pole)

SZ-021 (For $\phi 17.3\text{mm}$ Pole)



Mounting Dimensions

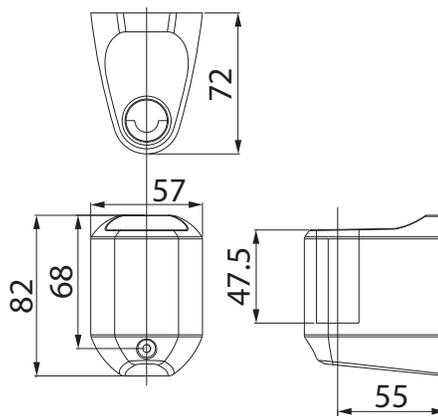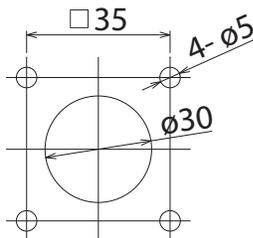

Wire connector SZ-020-001 (Sold Separately)

MP-B

Signal Tower Option



Ø30

85 db at 1m

Electronic Sound 1




FEATURES

- Double-insulation for enhanced durability and safety
- Direct mount installation with just a single screw
- Main body made of heat resistant ABS resin for superior impact resistance
- Compatible with the MP and MPS Signal Tower
(The Red module is required when using the optional MP-B)

Part Names and Dimensions

- Operates in conjunction with the Red LED module (Alarm activation with other colors must be special ordered).

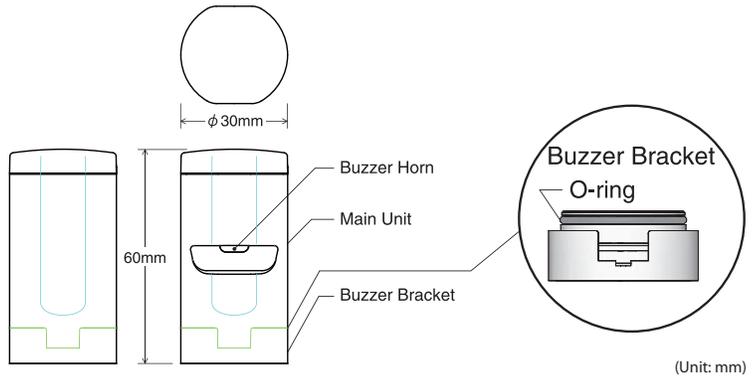

Specifications

Model	Rated Voltage	Sound Level	Power Consumption
Ⓞ MP-B	AC/DC 24V	80dB (at 1m)	0.7W

Ⓞ Requires Red LED Module

DEB




LED Lamp

FEATURES

- LED Color emits a Warm White color
- Suitable lighting for Patlite Compatible Rotating Lamp Series.
- Replacable with AC Lamp Bulbs for Patlite Products.

COMPATIBLE MODELS:

SKH-110A/120A, SKHB-100A/200A, SKH-100EA/200EA
 RH/RK(B)-100A/120AUL/200A/240AUL
 WH/WK(B)(S)-100A/200A
 KJS(B)-110/210/310/120/220/320
 KJ(B)-110/210/310/410/120/220/320/420
 KJT-110/210/310/120/220/320

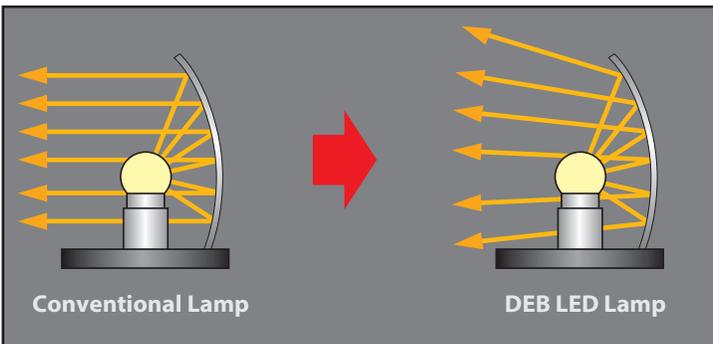

Specifications

Model	Rated Voltage	Power Consumption	LED Color	Lamp Base	Mass
DEB-15SBA-CL	AC 12V	1.7W (at AC13.5V)	Warm White	BA15S	9.8g

Mounting Pole

φ50 (φ40)


SZ-60L
SZ-80L





SZ-60T



SZ-60L

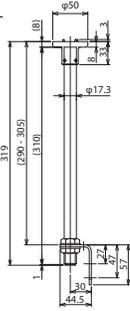

SZ-80L

 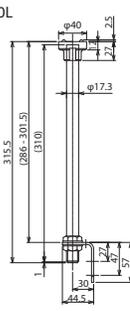


Includes SZ-011

Includes SZ-012

φ60

SZ-70L

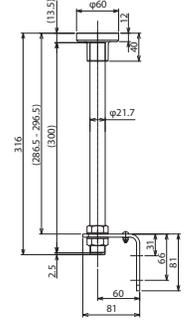

Includes SZ-013

φ70

SZ-50L




SZ-50T




SZ-40L




SZ-40T

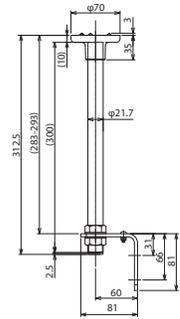


Includes SZ-013

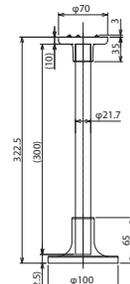

Includes SZ-010

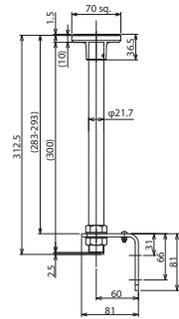

Includes SZ-013

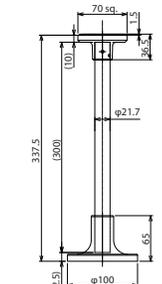


Includes SZ-010

φ81

SZ-30L




SZ-30T

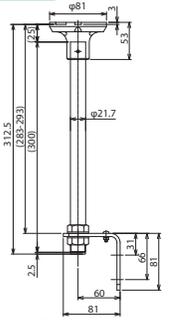

Includes SZ-013

Cannot use with Rubber Gasket.

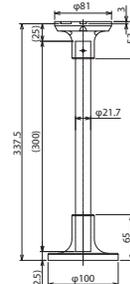

Includes SZ-010

Cannot use with Rubber Gasket.

Model	Material					
	Upper Bracket	Pole	'L' Bracket	Cord Bushing	Mounting Bracket	Compatible Models
SZ-80L	ABS Resin	Carbon-steel Pipe	SPHC	6/6 Nylon	—	LCE-W
SZ-60L	ADC12		SPHC	6/6 Nylon	—	LE-W, LES-AW
SZ-60T	—	—	—	—	ADC12	—
SZ-70L	ABS Resin	Carbon-steel Pipe	SPHC	EPT	—	LME-W
SZ-50L	ADC12		SPHC	EPT	—	LU7, LHE-A
SZ-50T	—	—	—	—	ADC12	—
SZ-40L	ADC12	Carbon-steel Pipe	SPHC	EPT	—	KUS
SZ-40T	—		—	—	ADC12	—
SZ-30L	ABS Resin		SPHC	EPT	—	RLE, RU, RH, PS, PES-A
SZ-30T	—	—	—	—	ADC12	—

ADC12: Aluminum Alloy Die-cast SPHC: Hot Rolled Milled (Sheet) Steel
EPT: Ethylene Propylene Rubber

Mounting Bracket

SZ-010







SZ-011




SZ-016A

SZ-70-B

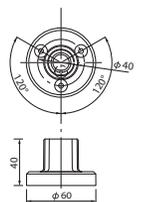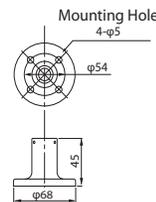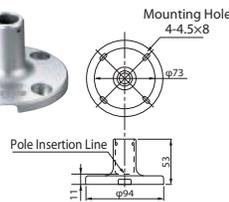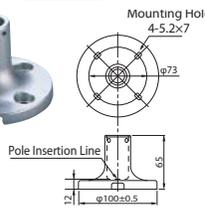

SZ-014

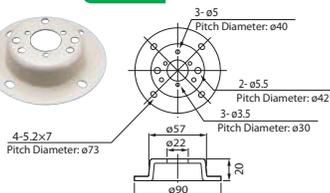

Model	Material	Compatible Models
SZ-010	Aluminum Alloy Die-cast	RUP, LME, LMS, LHE
SZ-011		LCE, LCS, LE, LES-A
SZ-016A	Cold-rolled Milled Steel	LUS, LU7, RUP, LME, LMS, LHE
SZ-014		LE, LES-A
SZ-70-B	ABS	φ21.7mm Pole

LS7 Options

Wall Mounting Bracket SZ-110



SZ-110

SZ-110S

SZ-110D

Multi-mount Bracket SZ-130



SZ-130

SZ-130S

SZ-130D

Platform Bracket SZ-100




SZ-100

SZ-100S

SZ-100D

Front (Audible Alarm Opening)

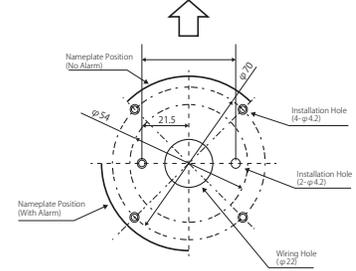

Outer Cover for LS7*
Part No.:
B45110011-F1

Replacement Parts



O-ring for LS7
Part No.:
Z35721039-F1



Mount Cover for LS7 (Accessory)
Part No.:
B81910001-F1



M12 Connector & Cable
SZ-120-02 Cable Length 2m (XS2F-D821-DH0-R)
SZ-120-05 Cable Length 5m (XS2F-D821-GH0-R)
SZ-120-10 Cable Length 10m (XS2F-D821-JH0-R)
* Only for connecting to the LS7.

CLA Options



Option

Rear Attachment
(Magnetic Mount)
Model SZ-310ARM



Option

Side Attachment
(Screw Mount)
Model SZ-310AS



Option

Side Attachment
(CLB-24N Compatible)
Model SZ-310ASB



Option

Rear Attachment
(Stainless Steel Screw Mount)
Model SZ-310EU

CLK Options

M12 Quick Disconnect



4-wire M12 Socket Cable, 5m (No. 1536308)
4-wire M12 SUS Socket Cable, 5m (No. 1552447)

Daisy Link at a maximum of 5 Units



4-wire M12 Link Cable, 0.6m (No. 1518892)
4-wire M12 SUS Link Cable, 0.6m (No. 1552638)

One-touch Installation



CLK-001

Angle Adjustment Bracket



SZ-320KS

Surface-mounting Bracket




SZ-330KP


NHL Options



Wall Mount Bracket NH-WST

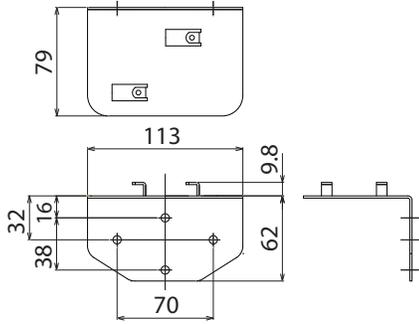



Partition Bracket NH-PST

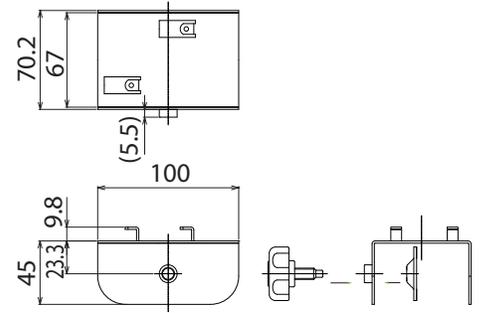

BKV Options

BK-001 Size Adjustment Bracket

This bracket is used to install the annunciator in a place where holes have already been drilled for legacy PATLITE Products (φ133mm² Type)

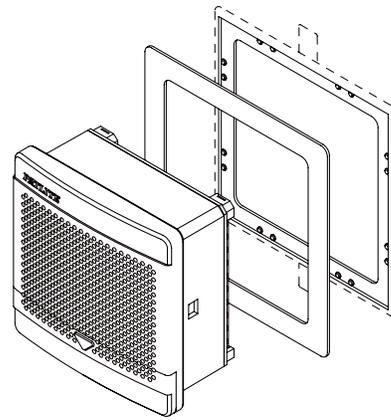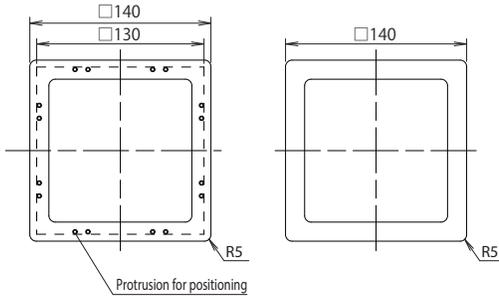


RFT/RFV Options

Wall Mount Bracket



RF-001 Wall Mount Bracket

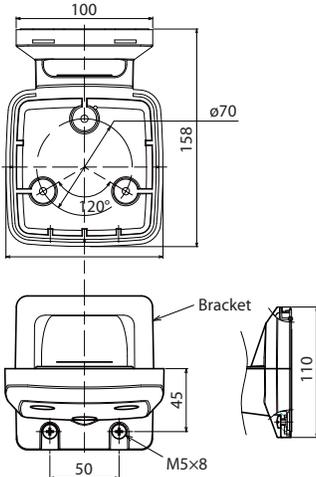


(Unit: mm)

Ceiling Mount Bracket







RF-002 Ceiling Mount Bracket



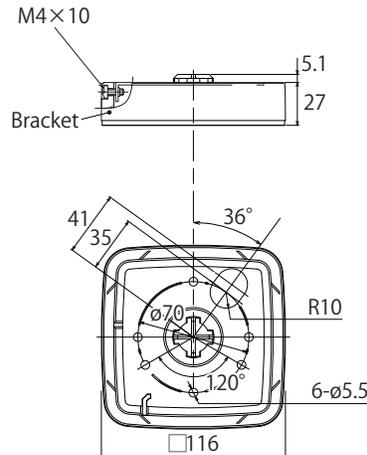



(Unit: mm)



    Replacement Bulbs

Model	Bulb No.	Ratings	Part No.
 RP35/BA15S	1	12V 35W	D01203501-F1
	2	24V 35W	D02403501-F1
 RP35/BA15D	5	48V 35W	D04803502-F1
 G18/BA15S	8	6V 3W	D00600303-F1
	9	12V 10W	D01201003A-F1
	10	24V 10W	D02401003A-F1
	11	48V 10W	D04801003-F1
	12	12V 5W	D01200503A-F1
 T20/E12	13	30V 10W	D03001006A-F1
	14	110V 10W	D11001006A-F1
	15	220V 10W	D22001006A-F1
	16	110V 15W	D11001506A-F1
	17	220V 15W	D22001506A-F1
 G14/BA9S	18	12V 6W	D01200604-F1
	19	24V 6W	D02400604-F1
 T10/E10	22	110V 3W	D11000307-F1
	27	12V 0.11A	D012/1107-F1
	28	24V 0.11A	D024/1107-F1
 RP35/BA15D	36	120V 40W (Vibration Resistant)	D12004024-F1
	37	220V 30W	D22003024-F1

   Model	Bulb No.	Ratings	Part No.
 Vibration Resistant	39	28V 11W	D02801111-F1
 T20/BA15D	40	110V 12W	D11001211-F1
	41	250V 11W	D25001111-F1
 S25/BA15S	42	12V 23W	D01202305-F1
	43	24V 25W	D02402505-F1
 Vibration Resistant	50	28V 20W	D02802011-F1
 T20/BA15D			
 Vibration Resistant	51	110V 20W	D11002011-F1
 T20/BA15D	53	250V 20W	D25002011-F1
	 G18/BA15S	54	12V 15W
55		24V 20W	D02402003-F1

 	9	AC12V (50/60Hz) 1.7W (at 13.5VAC)	DEB-15SBA-CL
---	---	--------------------------------------	--------------

* Some bulbs may not be available due to part or product discontinuation without prior notice.

Look for this Mark:

Model **DEB LED Lamp**

Recommended Product

For more details on Model DEB
Refer to the "Replacement Bulb"
Section at the end of this Catalog

