

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing



1345274

<https://www.phoenixcontact.com/in/products/1345274>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B48, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 5, straight, M25, height: 107.5 mm, cable gland: none, Standard

Your advantages

- Good shielding in the event of electromagnetic interference

Commercial data

Item number	1345274
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	AF7APB
GTIN	4063151658649
Weight per piece (including packing)	580.8 g
Weight per piece (excluding packing)	580 g
Customs tariff number	85389099
Country of origin	CN

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing



1345274


<https://www.phoenixcontact.com/in/products/1345274>

Technical data

Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Application	Standard
Type	B48
No. of cable outlets	5
Type of the screw connection	M25
Cable outlet	straight
Pg screw connection	none

Dimensions

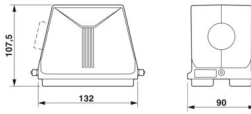Dimensional drawing	
Width	90 mm
Height	107.5 mm
Length	132 mm

Material specifications

Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated

Mechanical properties

Mechanical data

Type of the screw connection	M25
Locking type	Pin

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
	IP67
Enclosure rating (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing


1345274

<https://www.phoenixcontact.com/in/products/1345274>



Drawings

Dimensional drawing

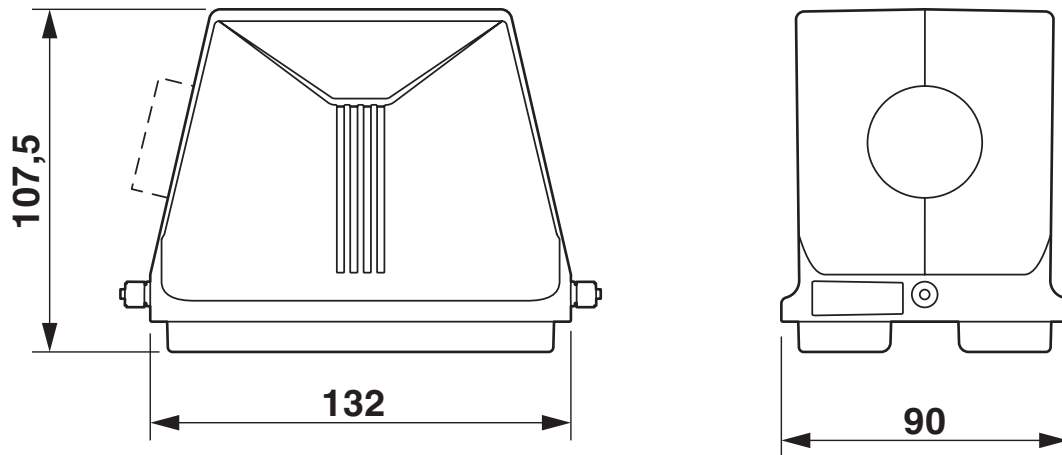

Dimensional drawing

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing



1345274

<https://www.phoenixcontact.com/in/products/1345274>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1345274>



cUL Recognized
Approval ID: E255026



UL Recognized
Approval ID: E255026

cULus Recognized

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing



1345274

<https://www.phoenixcontact.com/in/products/1345274>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing



1345274

<https://www.phoenixcontact.com/in/products/1345274>

Accessories

G-INS-M25-M68N-NNES-S - Cable gland

1411165

<https://www.phoenixcontact.com/in/products/1411165>



Cable gland, material for screw connection: Brass, nickel-plated, application: Standard, external cable diameter 11 mm ... 17 mm, shielding: no, connecting thread: M25 x 1.5, color: silver, with O-ring

G-INSEC-M25-S68N-NCRS-S - Cable gland

1411190

<https://www.phoenixcontact.com/in/products/1411190>



Cable gland, material for screw connection: Brass, nickel-plated, application: EMC, external cable diameter 11 mm ... 16 mm, shielding: yes, connecting thread: M25 x 1.5, color: silver, with O-ring

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing

1345274

<https://www.phoenixcontact.com/in/products/1345274>



HC-M-KV-M25(1ASI) - Cable gland

1584020

<https://www.phoenixcontact.com/in/products/1584020>



Metal screw connection for an AS-Interface flat-ribbon conductor, thread type M25

US-EMLP (20X9) CUS - Plastic label

0830085

<https://www.phoenixcontact.com/in/products/0830085>



Plastic label, Card, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, Number of individual labels: 75, text field height: 9 mm, text field width: 20 mm

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing

1345274

<https://www.phoenixcontact.com/in/products/1345274>



US-EMLP-HA (20X9) - Plastic label

0830989

<https://www.phoenixcontact.com/in/products/0830989>



Plastic label, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: adhesive, Number of individual labels: 70, text field height: 9 mm, text field width: 20 mm

WP-G HF IP66 M25 BK - Protective hose screw connection

3240899

<https://www.phoenixcontact.com/in/products/3240899>



Cable gland, metric thread, IP66 protection, straight

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing

1345274

<https://www.phoenixcontact.com/in/products/1345274>



WP-G HF IP69K M25 BK - Protective hose screw connection

3240885

<https://www.phoenixcontact.com/in/products/3240885>

Cable gland, metric thread, IP68/69k protection, straight



WP-GA HF IP66 M25 BK - Protective hose screw connection

3240927

<https://www.phoenixcontact.com/in/products/3240927>

Cable gland, metric thread, IP66 protection, angled



HC-STA-B48-HHFS-5TTM25-EM-AL - Housing

1345274

<https://www.phoenixcontact.com/in/products/1345274>



WP-GA HF IP69K M25 BK - Protective hose screw connection

3240913

<https://www.phoenixcontact.com/in/products/3240913>

Cable gland, metric thread, IP68/69k protection, angled



WP-GR HF IP66 M25 BK - Protective hose screw connection

3240955

<https://www.phoenixcontact.com/in/products/3240955>

Cable gland, metric thread, IP66 protection, with strain relief



HC-STA-B48-HHFS-5TTM25-EM-AL - Housing

1345274

<https://www.phoenixcontact.com/in/products/1345274>



WP-GR HF IP69K M25 BK - Protective hose screw connection

3240941

<https://www.phoenixcontact.com/in/products/3240941>



Cable gland, metric thread, IP68/69k protection, with strain relief

WP-G PP HF M25 - Protective hose screw connection

3240999

<https://www.phoenixcontact.com/in/products/3240999>



Cable gland made from PP with metric thread, IP65 protection

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing

1345274

<https://www.phoenixcontact.com/in/products/1345274>

WP-GT PP HF M25 - Protective hose screw connection

3241013

<https://www.phoenixcontact.com/in/products/3241013>



Cable gland made from PP with metric thread, rotatable, IP54 protection

WP-G BRASS IP40 M25 - Protective hose screw connection

3241048

<https://www.phoenixcontact.com/in/products/3241048>



Cable gland made from brass with metric thread, IP40 protection

HC-STA-B48-HHFS-5TTM25-EM-AL - Housing



1345274

<https://www.phoenixcontact.com/in/products/1345274>

WP-GT BRASS M25 - Protective hose screw connection

3241034

<https://www.phoenixcontact.com/in/products/3241034>

Cable gland made from brass with metric thread, rotatable, IP40 protection



WP-G BRASS IP65 M25 - Protective hose screw connection

3241062

<https://www.phoenixcontact.com/in/products/3241062>

Cable gland made from brass with metric thread, IP65 protection



Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in