


PHE L070HUB

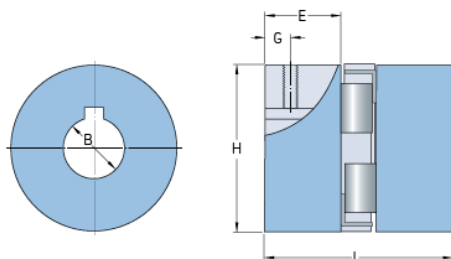

Size	70
Position threaded hole G (mm)	9.5
Position threaded hole G (in)	0.37
Outer diameter H (mm)	35
Outer diameter H (in)	1.38
Maximum bore	19
Maximum bore (in)	-
Set screw	M6
Length E (mm)	19
Length E (in)	0.75
Bore	9
Bore (in)	0.35