


# NENV Straight Connector Ex e Non Metallic System

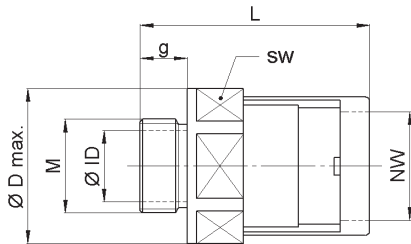

## Features

- Prevents electrostatic charging
- For indoor and outdoor applications
- High thread and system connection strengths
- Easy installation
- Very good chemical properties

## Approvals



## Certification & Standards

<b>Approved to:</b>	IEC EN 60079-0, 60079-7, 60079-31
<b>EC TYPE Examination Certificate:</b>	ATEX: SEV 15 ATEX 0107X IECEX: IECEX SEV15.0001X Ex e IIC Gb Ex tb IIIC Db
<b>Temperature:</b>	-5°C to +85°C Sizes 02-03 -20°C to +85°C Sizes 04-08
<b>IP protection:</b>	IP68

Compatible with: XESX Conduit / Materials: Anti-Static Nylon 12 with Nickel Plated Brass Thread / Colour: ● Black

Part No.	Thread Size (mm)		Conduit Size (mm)		Dimensions (mm)				Weight kg/100	GID Codes
	Metric	Metric	Metric	NW	g	Ø ID	Ø D max	L		
NENV0203	16	12	10	10	9.5	24	40	19	1.8	7TCA297120R0337
NENV0303	16	16	12	10	9.5	26	43	24	2	7TCA297120R0338
NENV0404	20	20	17	10	13.5	33	51	30	3.1	7TCA297120R0340
NENV0505	25	25	23	11	18.5	39	54	36	4.2	7TCA297120R0341
NENV0606	32	32	29	13	25	50	57.3	46	6.2	7TCA297120R0342
NENV0707	40	40	36	13	32.5	59	71.4	55	10.9	7TCA297120R0343
NENV0808	50	50	48	14	41.5	71	72.4	65	16.9	7TCA297120R0344
NENV0809	63	50	48	14	51.5	75	72.4	65	16.5	7TCA297120R0345

