

- Products Categories**
- Part No. index
  - Cutters & Pliers
  - Wire strippers
  - Crimpers
  - Tweezers
  - Screwdrivers & Wrenches
  - Metal working
  - Parts cases
  - Tool cases
  - Tool kits
  - Soldering irons & Solder
  - Parts & Solder removal equipment
  - Measuring instruments
  - Optical equipment
  - Antistatic products
  - Clean products
  - Maintenance & Safety products





Antistatic products > Rubber mats

**F-840 / 841 / 843** ESD FLOOR MATS



Part No.	Part Name	External dimensions mm	ESD standard Ω	Weight g
F-840	ESD FLOOR MAT	300 (W) × 300 (D)	Ground resistance Rg 1×10 <sup>7</sup>	310
F-841-A	ESD Floor mat (Type A)	75 (W) × 375 (D)		150
F-841-B	ESD Floor mat (Type B)			
F-843-A	ESD Floor mat (Type A)	75 (W) × 300 (D)		120
F-843-B	ESD Floor mat (Type B)			

■ Thickness: 10 mm

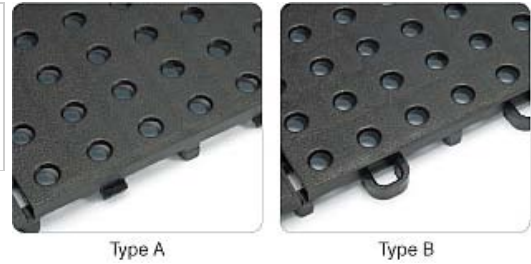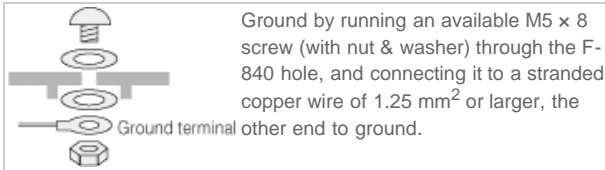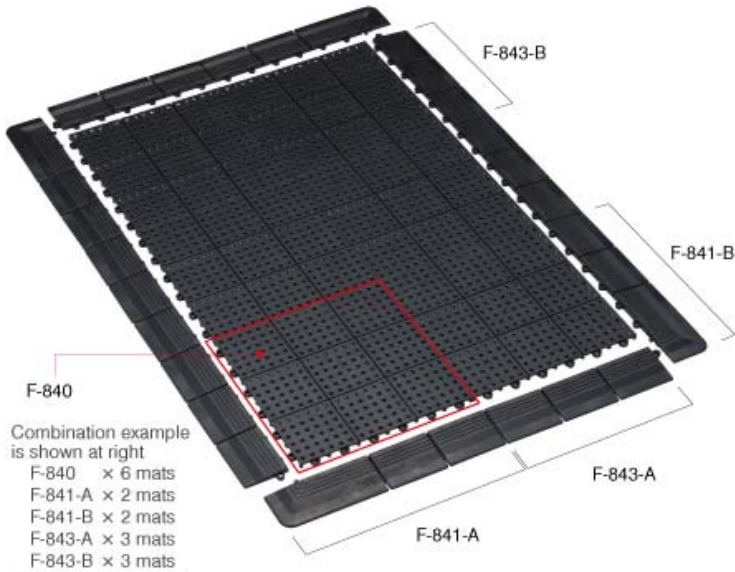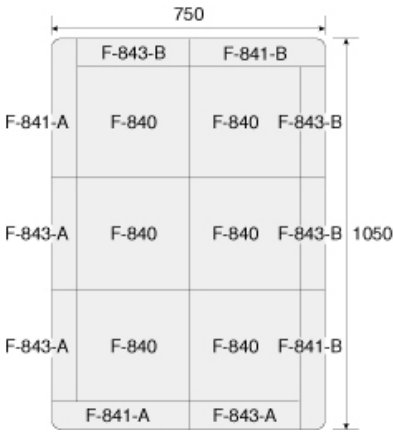

**Related products**

**F-127** GROUND CORD

- Wire dia. × length: 1.25 mm<sup>2</sup> × 2 m
- Quantity: 2-piece pack

**F-127-1** TERMINAL SET

- Wire dia. × length: 1.25 mm<sup>2</sup> × 2 m
- Quantity: 2-piece pack




**F-27** GROUND CORD

- Wire dia. x length: 1.25 mm<sup>2</sup> x 2 m
- For conductive (ESD) rubber mat
- Quantity: 2-piece pack




**F-29-1** STUD

- Application: For use with conductive rubber mats
- Quantity: 5-piece pack

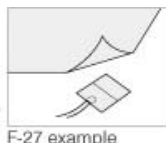

**F-28** GROUND PLATE

- For conductive rubber mat
- Quantity: 10-piece pack

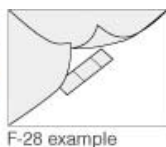

**F-29-2** PUNCH KIT

- Quantity: 1 set (punch & chisel)



**F-29** GROUND CORD

- Wire dia. x length: 0.75 mm<sup>2</sup> x 1m
- With 1 MΩ resistor



Example of pre-cut hole & clinching stud

**F-24** GROUND CORD

- With 1 MΩ resistor

