




Diffuse reflection sensor with background suppression

OJH-HPKG/SO/AS

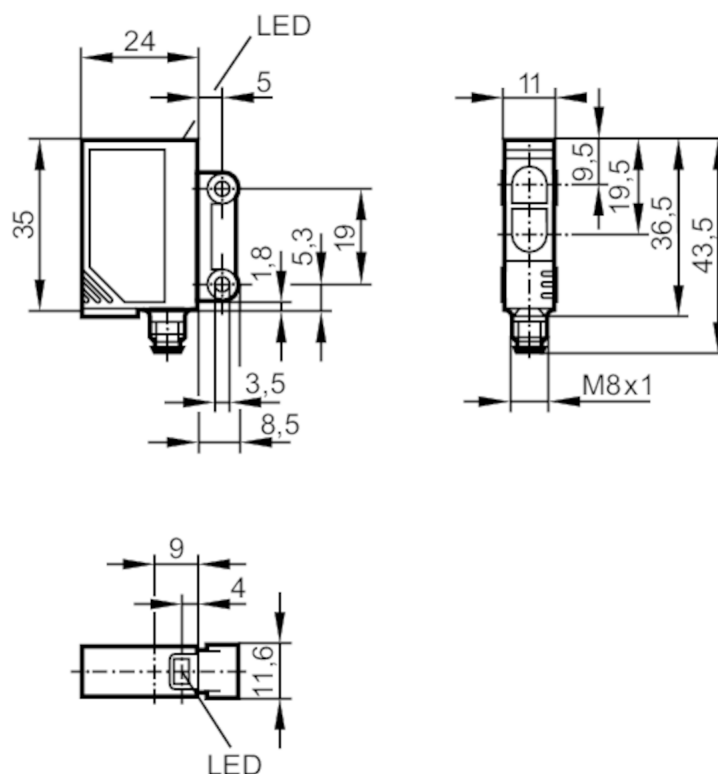

receiver in upper lens
transmitter in lower lens



Product characteristics

Type of light	red light
Housing	rectangular

Application

Special feature	Background suppression
Function principle	Diffuse reflection sensor

Electrical data

Operating voltage	[V]	10...30 DC
Current consumption	[mA]	25
Protection class		III
Reverse polarity protection		yes
Type of light		red light
Wave length	[nm]	660

Outputs

Electrical design		PNP
Output function		light-on mode
Max. voltage drop switching output DC	[V]	2.5
Permanent current rating of switching output DC	[mA]	200



Diffuse reflection sensor with background suppression

OJH-HPKG/SO/AS

Switching frequency DC	[Hz]	1000
Short-circuit protection		yes
Type of short-circuit protection		pulsed
Overload protection		yes

Detection zone		
Range	[mm]	< 100; (fixed)
Range adjustable		no
Max. light spot diameter	[mm]	13
Light spot dimensions refer to		at maximum range
Background suppression available		yes

Operating conditions		
Ambient temperature	[°C]	-25...60
Protection		IP 67

Tests / approvals		
EMC		EN 60947-5-2
MTTF	[years]	551

Mechanical data		
Weight	[g]	15.7
Housing		rectangular
Dimensions	[mm]	35 x 11 x 24
Materials		ABS; SEPS
Lens material		PMMA
Lens alignment		side lens

Displays / operating elements		
Display	switching status	1 x LED, yellow

Remarks		
Remarks		operating voltage "supply class 2" according to cULus
Pack quantity		1 pcs.

Electrical connection

Connector: 1 x M8; coding: A





Diffuse reflection sensor with background suppression

OJH-HPKG/SO/AS

Connection

