



ENGLISH

Datasheet

RS PRO 4 AND 8 POLE AUDIO CONNECTORS

Stock No: 2080628



4 Pole plug with PVC Cable
Grommet Blue nut is standard.
Dimensions: 29 x 28 x 93mm
Part No. RS1245



4 Pole plug without PVC Cable
Grommet Blue nut is standard.
Dimensions: 29 x 28 x 68mm
Part No. RS1250



4 Pole Cable Socket with PVC
Cable Grommet. Blue nut is
standard. Dimensions: 28 x 28 x
93mm **Part No. RS1255**

Plug Specification

Maximum Current: 20A.

Withstanding Voltage: $\geq 1400V$

Insulation Resistance: $\geq 1G\Omega$

Contact Resistance: $\leq 3m\Omega$

Solderability: $\leq 3S$

Insertion Force: 10-80N Minimum

Life: ≥ 2000


rspro.com



4 Pole Chassis Socket


Compatible with all previous 4 Pole Plugs
Dimensions: 24 x 24 x 33mm

Part No: **RS1270** with CSK Hole
RS1270X with Plain Hole

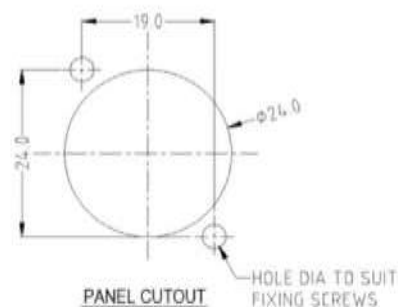


4 Pole Chassis Socket (Large Square Type)
Compatible with all previous 4 Pole Plugs
Dimensions: 40 x 40 x 33mm

Part No: **RS1275**

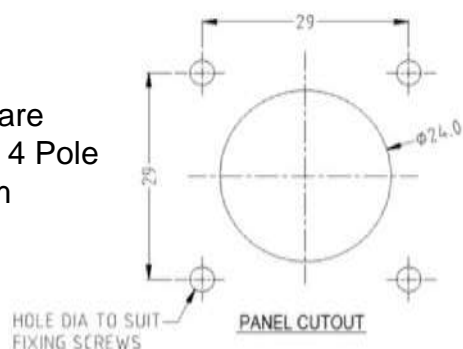

4 Pole Chassis Socket (Round Type)
Compatible with all previous 4 Pole Plugs
Dimensions: 50 x 50 x 33mm

Part No: **RS1280**

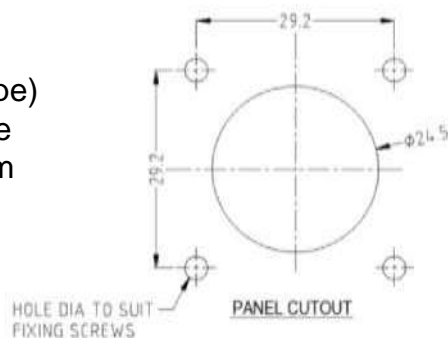

8 Pole Chassis Socket (Round Type)
Dimensions: 51 x 51 x 33mm

Part No: **RS1285**

