


Datasheet

PET, Rubber Vee Friction Belt, belt section B

RS Stock number 471-904

B Section Classical Wrapped Vee Belts

to API 1B, RMA IP 20, DIN 2215, ISO 4184 & BS3790

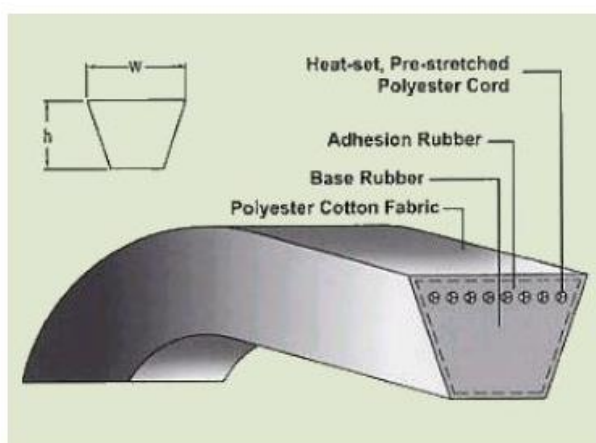

Dimensions w x h (mm)	Min. Pulley Diam. PCD (mm)	Std. Belt Lengths (mm)
17 x 11	125	650 - 7040

Description:

RS Z, A & B Section Belts

Special compounded stiff-yet-flex-crack resistant base

High modulus low stretch (hmls) polyester cords and length stabilisation process resulting in low stretch and maximum life

Polychloroprene impregnated poly-cotton jacket

Precision built belts requiring no matching or coding

Anti-static, heat, oil and abrasion resistant

Standards: API 1B, RMA IP 20, DIN 2215, ISO 4184 & BS3790

B Section - 17mm x 11mm - Wrapped Construction

Inside Length Li (ins)	Inside Length Li (mm)	Inside Length Li (ins)	Inside Length Li (mm)	Inside Length Li (ins)	Inside Length Li (mm)	Inside Length Li (ins)	Inside Length Li (mm)
B22.5	570	B48	1215	B91	2300	B151	3850
B23	585	B48.5	1225	B92	2337	B152	3861
B24	615	B49	1250	B93	2365	B154	3912
B25	630	B50	1275	B94	2388	B155	3937
B25.5	650	B51	1300	B94.5	2400	B156	3950
B26	660	B52	1320	B95	2413	B158	4000
B26.5	670	B52.5	1335	B96	2438	B162	4115
B27	686	B53	1350	B96.5	2450	B164	4165
B28	710	B53.5	1360	B97	2465	B165	4200
B28.5	725	B54	1372	B98	2500	B167	4250
B29	735	B55	1400	B99	2515	B170	4318
B29.5	750	B56	1425	B100	2540	B173	4394
B30	762	B57	1450	B101	2565	B175	4450
B30.5	775	B58	1475	B102	2600	B177	4500
B31	785	B59	1500	B103	2616	B180	4572
B31.5	800	B60	1525	B104	2650	B185	4700
B32	813	B61	1550	B105	2667	B187	4750
B32.5	825	B62	1575	B106	2700	B190	4826
B33	838	B63	1600	B107	2718	B193	4900
B33.5	850	B64	1625	B108	2750	B195	4953
B34	865	B65	1650	B109	2769	B197	5000
B34.5	875	B66	1675	B112	2845	B200	5080
B35	889	B67	1700	B113	2870	B204	5182
B35.5	900	B68	1725	B114	2900	B208	5280
B36	915	B69	1750	B115	2921	B210	5334
B36.5	925	B70	1775	B116	2950	B211	5359
B37	940	B71	1800	B117	2972	B216	5500
B37.5	950	B72	1825	B118	3000	B220	5600
B38	965	B73	1850	B120	3048	B224	5690
B38.5	975	B74	1880	B122	3099	B225	5700

**ENGLISH**

Inside Length Li (ins)	Inside Length Li (mm)	Inside Length Li (ins)	Inside Length Li (mm)	Inside Length Li (ins)	Inside Length Li (mm)	Inside Length Li (ins)	Inside Length Li (mm)
B39	991	B75	1900	B124	3150	B226	5740
B39.5	1000	B76	1930	B125	3175	B232	5893
B40	1016	B77	1950	B126	3200	B236	6000
B40.5	1030	B78	1981	B128	3250	B238	6045
B41	1040	B79	2000	B130	3300	B240	6096
B41.5	1050	B80	2032	B132	3350	B248	6300
B42	1060	B81	2060	B133	3375	B256	6500
B42.5	1075	B82	2083	B134	3400	B260	6600
B43	1090	B83	2100	B135	3425	B264	6700
B43.5	1100	B83.5	2120	B136	3450	B268	6800
B44	1120	B84	2134	B138	3500	B272	6900
B45	1150	B85	2160	B140	3550	B276	7000
B45.5	1163	B86	2200	B142	3600	B280	7100
B46	1175	B87	2210	B144	3658	B295	7500
B46.5	1180	B88	2240	B146	3700	B300	7620
B47	1200	B89	2260	B148	3750	B315	8000
B47.5	1207	B90	2286	B150	3810		