


Plug NOCC-M-S-SCRJG2PP-C5-PN

Part number: 5195381

FESTO

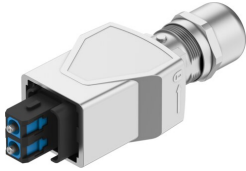

 General operating condition

Data sheet

Feature	Value
Conforms to standard	IEC 61754-24
Protocol	Ethernet PROFINET FOC
Additional functions	Fulfils requirements according to AIDA
Frequency of connection	100
Cable outlet	Straight
Product weight	84 g
Optical connection 1, connection type	Plug
Optical connection 1, design	Square
Optical connection 1, connection technology	SC-RJ to IEC 61754-24
Optical connection 1, number of pins/cores	2
Optical connection 1, occupied pins/wires	2
Optical connection 1, plug pattern	00995772
Optical connection 1, type of mounting	Push-pull with interlock against unintentional pulling
Optical connection 1, ferrule diameter	2.5 mm
Optical connection 2, connection technology	Lock nut
Tightening torque	0.42 Nm
Wire diameter	0.98 mm ... 1 mm
Type of wire	Polymer fibre
Wavelength	650 nm
Fire test	UL94 V-0
Cable diameter	5.5 mm ... 10 mm
Degree of protection	IP65 IP67
Note on degree of protection	In mounted state
Ambient temperature	-25 °C ... 70 °C
Storage temperature	-40 °C ... 70 °C
LABS (PWIS) conformity	VDMA24364-A1-L
Note on materials	RoHS compliant
Corrosion resistance class CRC	1 - Low corrosion stress
Material housing	Nickel-plated die-cast zinc
Housing colour	Silver
Material seals	NBR TPE
Ferrule material	Copper alloy